



Enclosed
automatic
transfer switches
ATS
ATP

Product designation

Product type designation

Voltage inputs

Maximum rated voltage Ue 400

Frequency range Hz 45...65

Current inputs

Rated current (Ie) A 45 (AC1)

Digital inputs

Number of digital input Nr. 6

Relay outputs

Number of relay output Nr. 7

Contact arrangement

6 with 1NO -
SPST 1 with
NO/NC - SPDT

Insulations

Voltage inputs

Rated insulation voltage Ui VAC 400
Rated impulse withstand voltage Uimp kV 4

Ambient conditions

Maximum Pollution degree 2

Overvoltage category 3


Housing

Material Metallic


Degree of protection IP65

Dimensions (W x H x D) mm 500x400x200

Dimensions

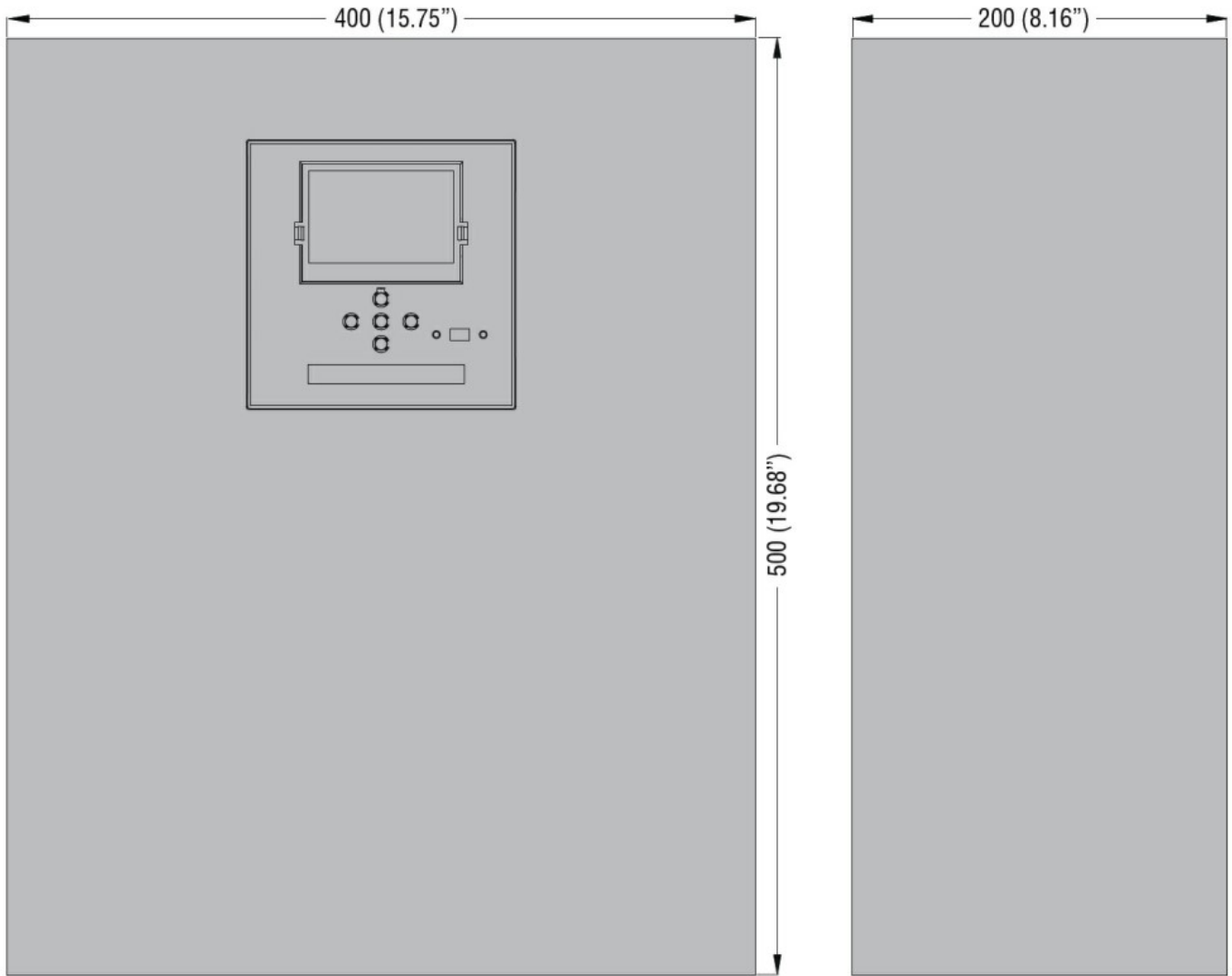

Wiring diagrams

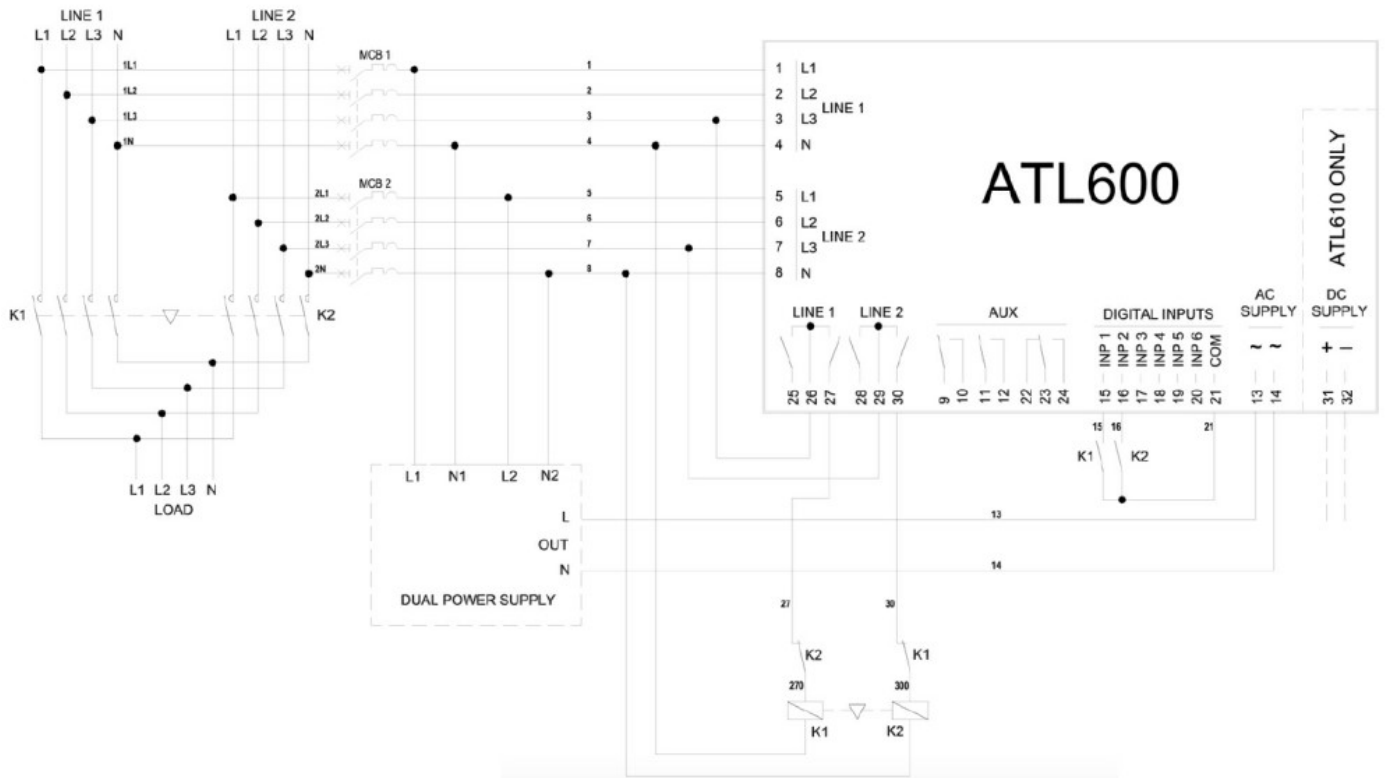

Certifications and compliance
Compliance

IEC 61439-2