



Enclosed automatic transfer switches ATS, with ATL600 controller and four-pole contactors, 60A ATP

Product designation

Product type designation

**General characteristics**

Number of controlled power sources	Nr.	2
Display		Backlit LCD graphic display 128x80 pixel
Languages	Nr.	5
<b>AC Power supply</b>		
Rated frequency	Hz	50/60
Operating frequency range	Hz	45...65
Immunity time for microbreakings	220VAC ms	≤250

**Voltage inputs**

Maximum rated voltage Ue		400
Frequency range	Hz	45...65
Measurement method		True root mean square (TRMS)

**Current inputs**

Rated current (Ie)	A	60 (AC1)
--------------------	---	----------

**Digital inputs**

Number of digital input	Nr.	6
-------------------------	-----	---

**Relay outputs**

Number of relay output	Nr.	7
Contact arrangement		6 x 1NO-SPST + 1 x C/O-SPDT
Electrical life	cycles	10 <sup>5</sup>
Mechanical life	cycles	10 <sup>7</sup>

**Interface**

Front optical USB communication port		Yes, with CX01 USB dongle (optional)
Front optical Wi-Fi communication port		Yes, with CX02 Wi-Fi dongle (optional)

**Insulations**

Voltage inputs	Rated insulation voltage Ui	VAC	400
	Rated impulse withstand voltage Uimp	kV	4

**Ambient conditions**


Maximum Pollution degree	2
Overvoltage category	3

**Housing**


Material	Metallic
Degree of protection	IP65

Dimensions (W x H x D)	mm	500 x 400 x 200
------------------------	----	-----------------

**Dimensions**

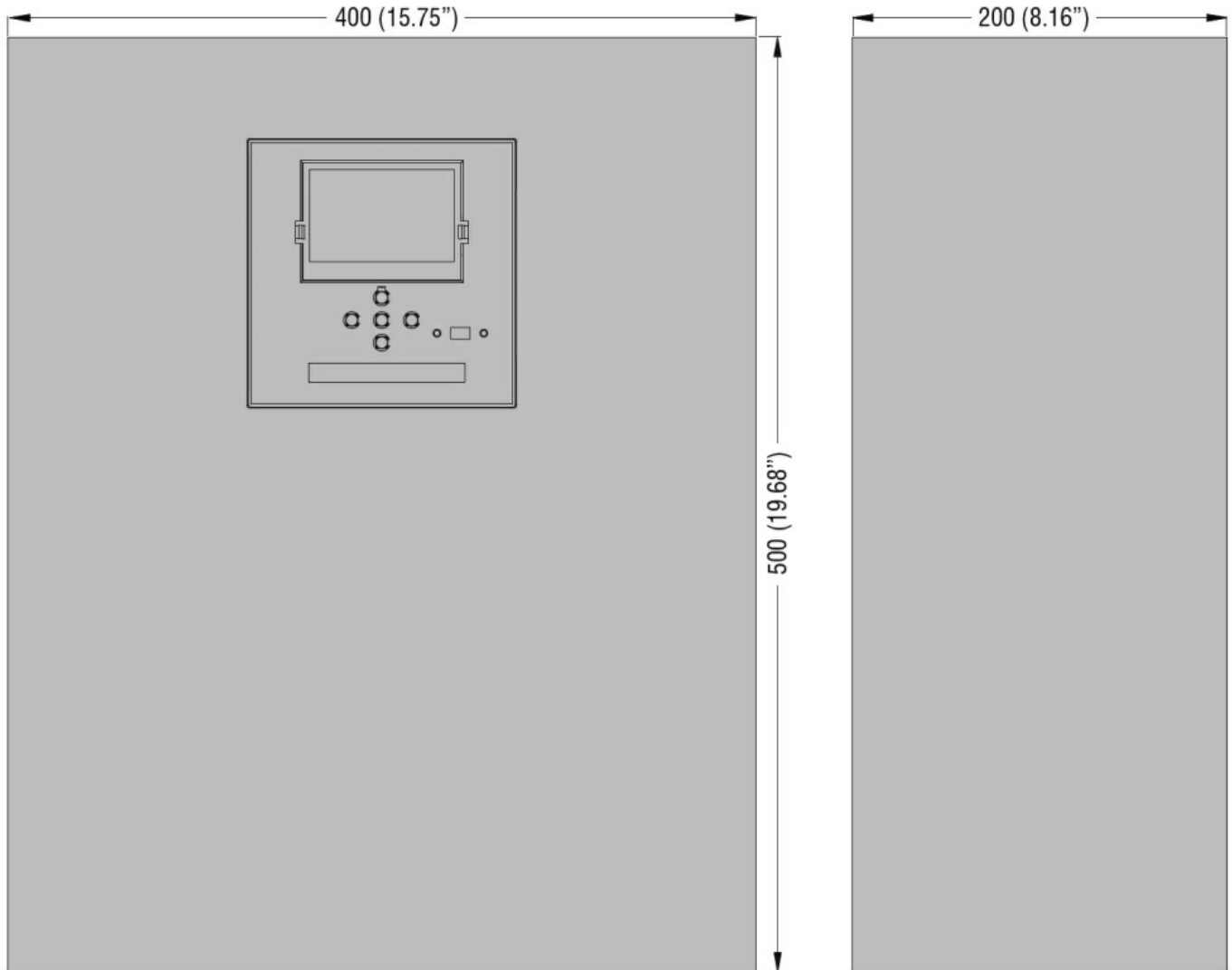

**Wiring diagrams**

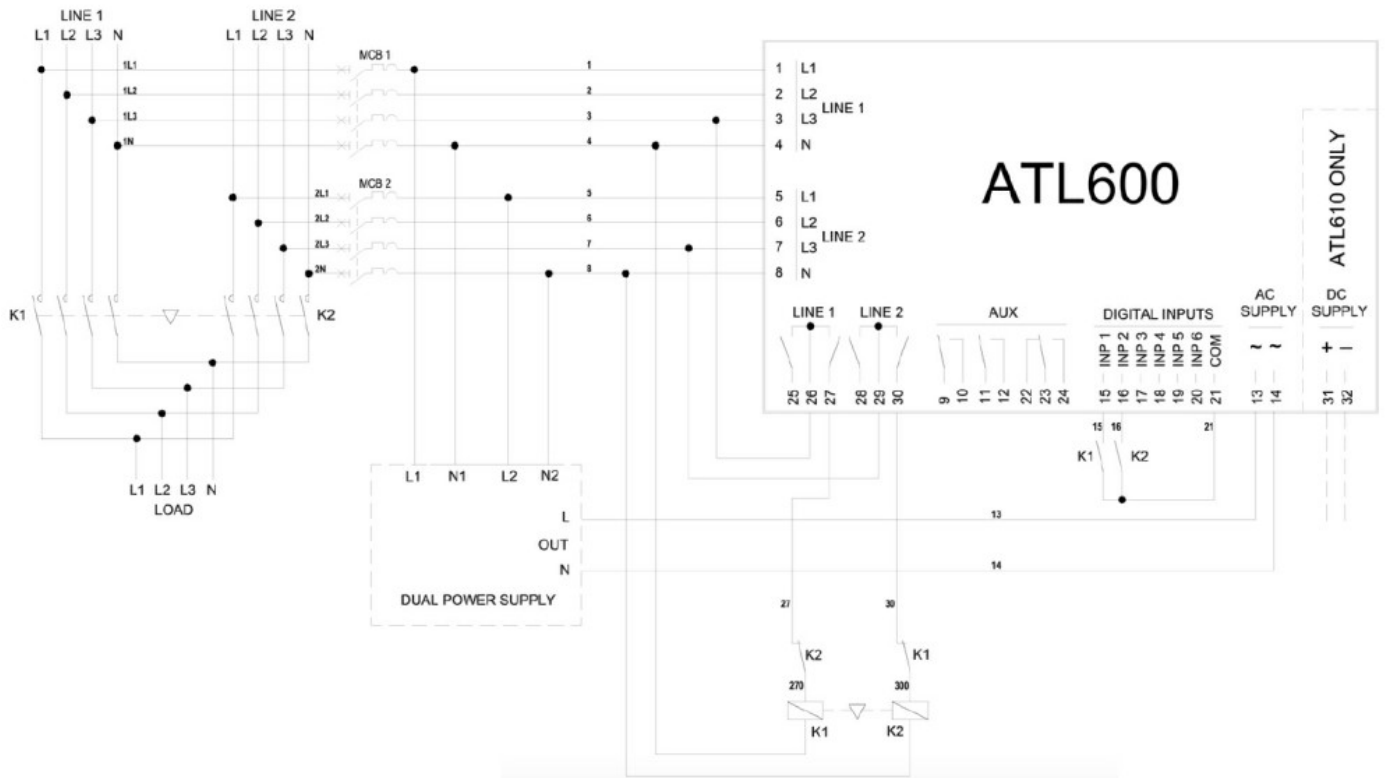

**Certifications and compliance**  
Compliance

IEC 61439-2