



Current transformers
DM2TA0250
Split-core

Product designation

Product type designation

Type of CT

Current inputs

Primary current I_{pn} (/5)	A	250
Operational frequency	min Hz	50
	max Hz	60
Secondary output current	A	5
Overload withstand I_{pn}	%	120
Burden	cl. 0.5 VA	1
	cl. 1 VA	2

Insulations

Rated insulation voltage U_i IEC/EN	V	720
IEC rated short-time thermal current I_{th}	I_{th} for s	40...60
IEC rated dynamic current I_{dyn}	I_{th} for s	2.5
Insulation dry type		Class E


Mechanical features

Terminals type	Screw
Fixing	Screw fixing
Weight	g 1050

Ambient conditions

Temperature	Operating temperature	min °C	-25
		max °C	+50
	Storage temperature	min °C	-40
		max °C	+80
Relative humidity		%	90
Protection degree			IP30

Dimensions

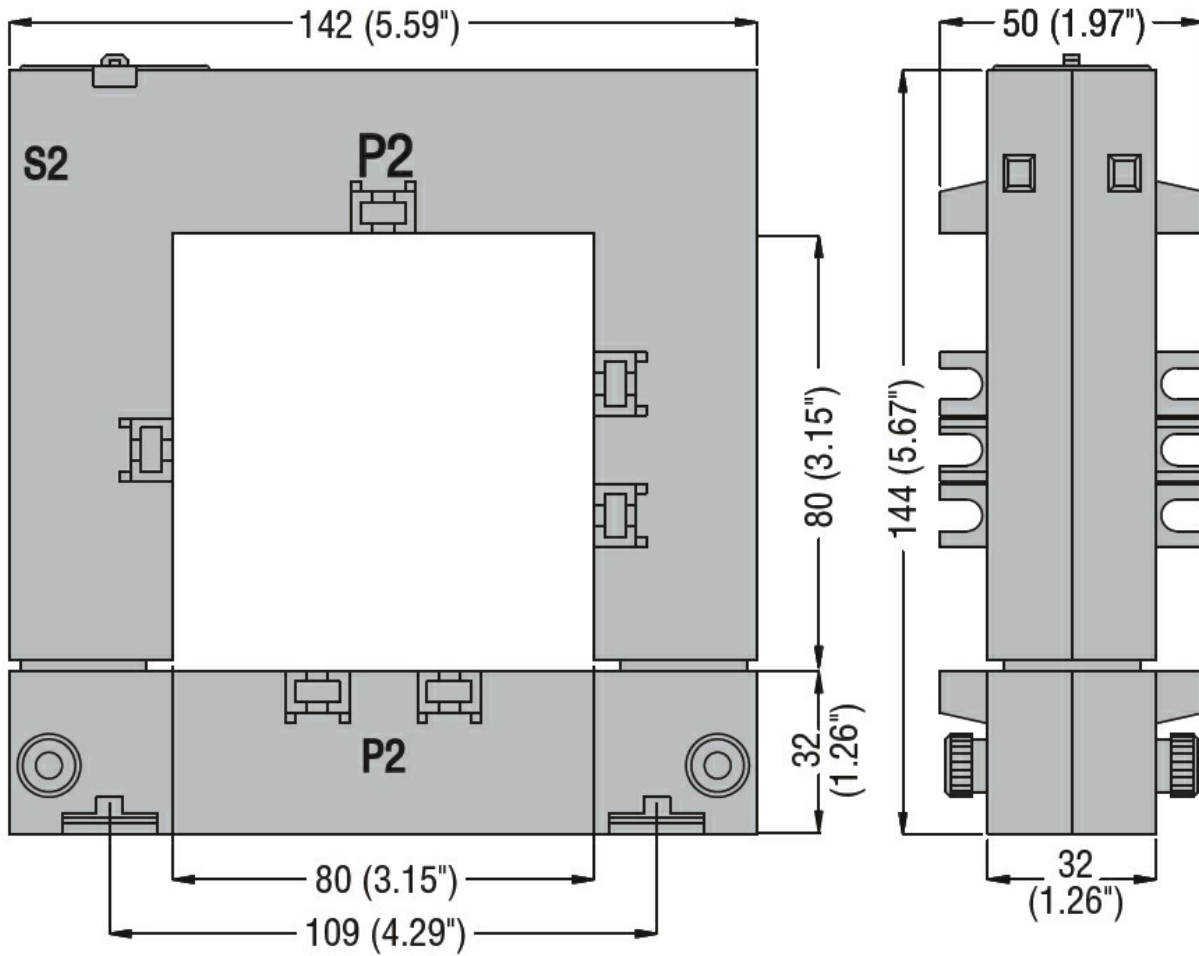

Certifications and compliance

Certifications

IEC/EN 60044-1

Compliance

EAC

ETIM classification

EC000066 - Power contactor, AC switching