



Product designation

Changeover
contactor
assemblies
BGC09

Product type designation

Electrical features

Maximum operating current ($\leq 440V$)

A 20

Contact characteristics

Operational current Ie

| | | |
|-----------------------------|---|----|
| AC-1 ($\leq 40^{\circ}C$) | A | 20 |
| AC-1 ($\leq 55^{\circ}C$) | A | 18 |
| AC-1 ($\leq 60^{\circ}C$) | A | 15 |

Rated operational power AC-1 ($T \leq 40^{\circ}C$)

| | | |
|------|----|----|
| 230V | kW | 8 |
| 400V | kW | 14 |
| 500V | kW | 16 |
| 690V | kW | 22 |

UL technical data

UL/CSA General Use

A 20

Mechanical features


Terminals type

Clamp screw


Weight

g 365

Dimensions

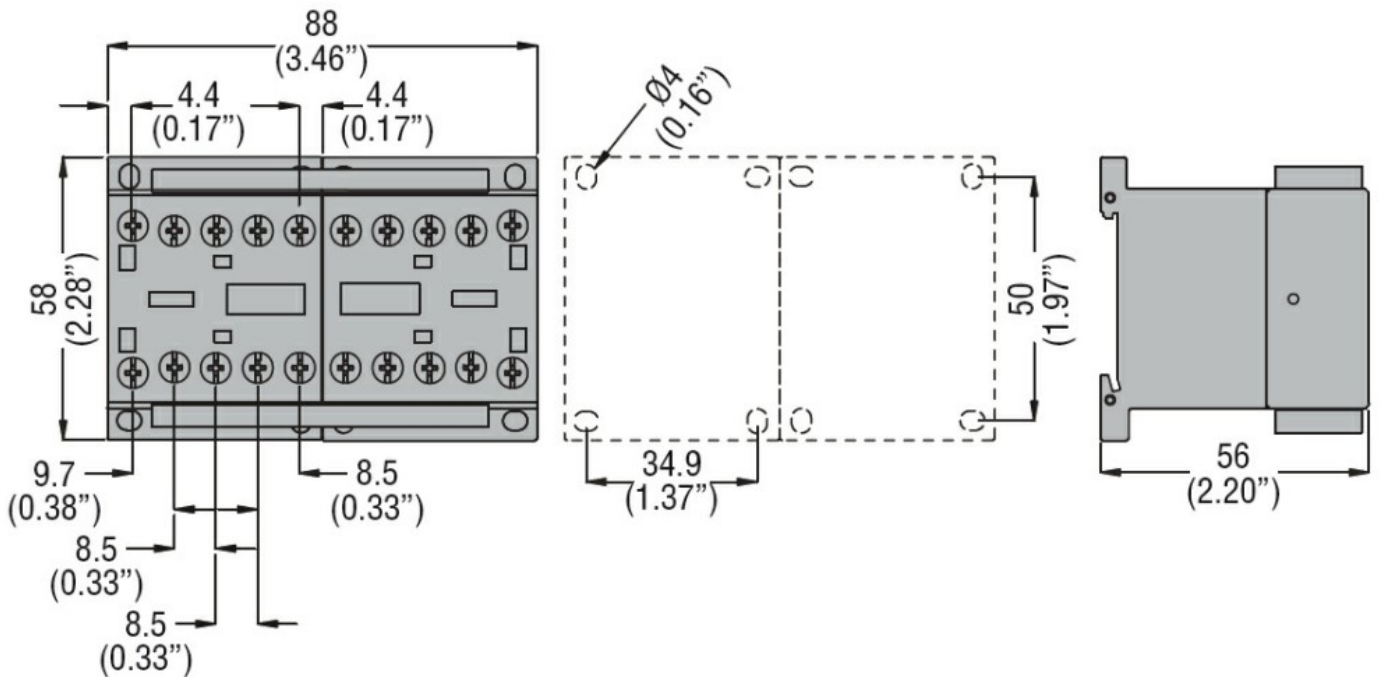

Wiring diagrams

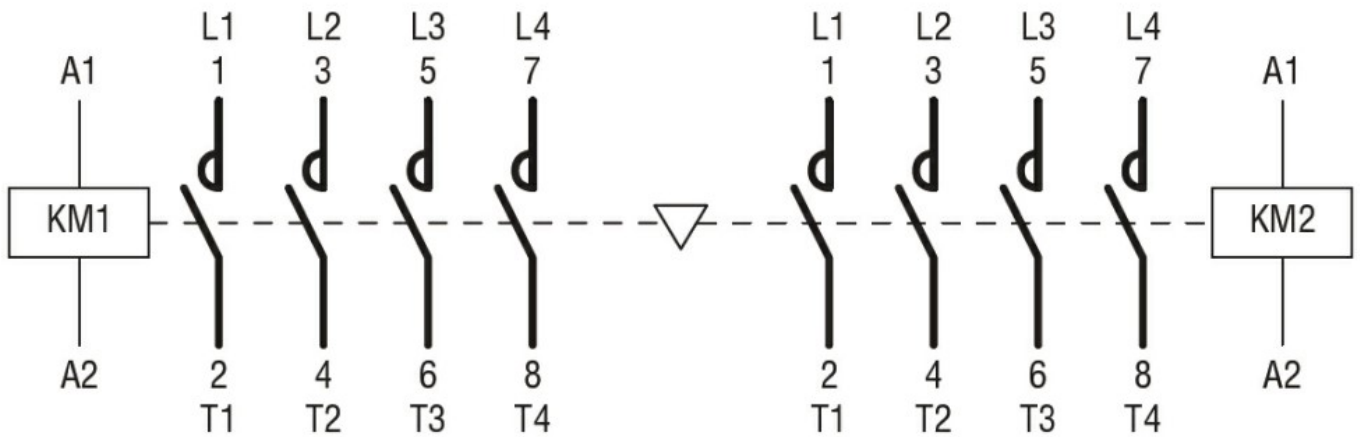

Certifications and compliance

Compliance

IEC/EN 60947-1
 IEC/EN 60947-4-1
 UL508 CSA C22.2 n° 14

Certificates

cULus

ETIM classification

ETIM 8.0

EC000010 -
 Combination of
 contactors