



Product designation

Changeover
contactor
assemblies
BGC09

Product type designation

Electrical features

Maximum operating current ($\leq 440V$)

A 20

Contact characteristics

Operational current I_{le}

AC-1 ($\leq 40^{\circ}C$)	A	20
AC-1 ($\leq 55^{\circ}C$)	A	18
AC-1 ($\leq 60^{\circ}C$)	A	15

Rated operational power AC-1 (T $\leq 40^{\circ}C$)

230V	kW	8
400V	kW	14
500V	kW	16
690V	kW	22

UL technical data

UL/CSA General Use

A 20

Mechanical features


Terminals type

Clamp screw


Weight

g 450

Dimensions

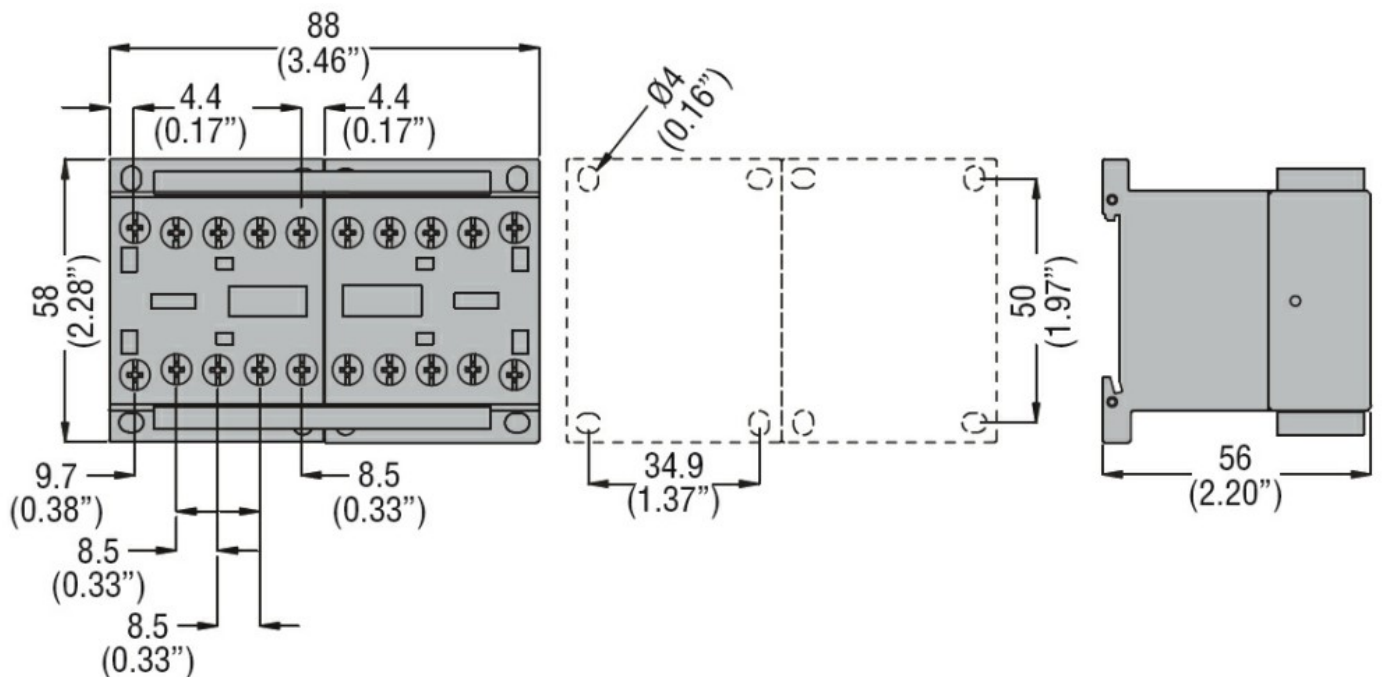

Wiring diagrams

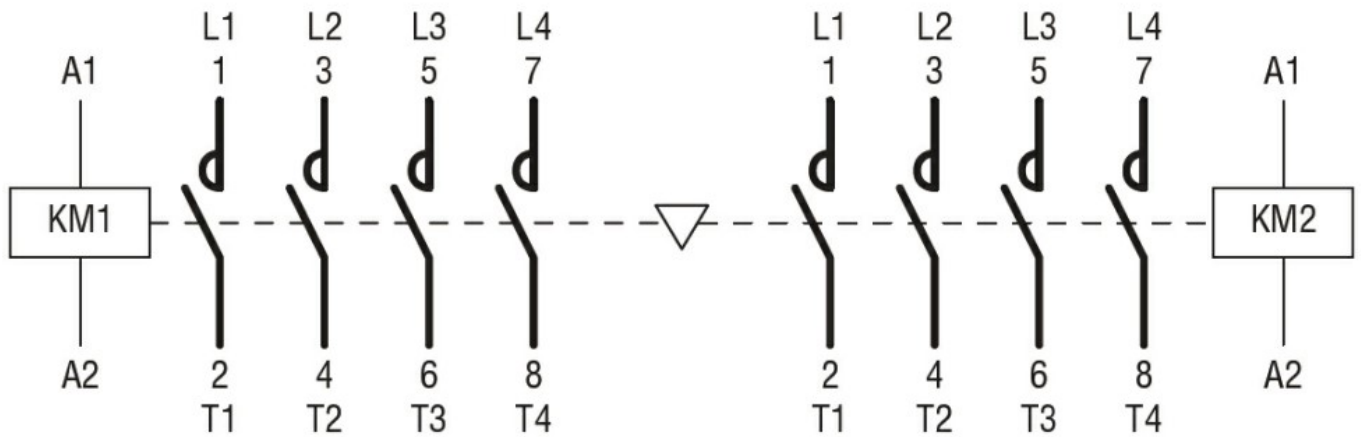

Certifications and compliance

Compliance

IEC/EN 60947-1
IEC/EN 60947-4-1
UL508 CSA C22.2 n° 14

Certificates

cULus

ETIM classification

ETIM 8.0

EC000010 -
Combination of
contactors