





Product designation				Reversing contactor
Product type designation				BGR12
<b>Electrical features</b>				
Maximum operating current ( $\leq 440V$ )	A			12
<b>Contact characteristics</b>				
Operational current Ie	AC-3 ( $\leq 440V \leq 55^{\circ}C$ )		A	12
<b>Rated operational power AC-3 (<math>T \leq 55^{\circ}C</math>)</b>				
	230V	kW	3.2	
	400V	kW	5.7	
	415V	kW	6.2	
	440V	kW	5.5	
	500V	kW	5	
	690V	kW	5	
<b>Built-in auxiliary contacts</b>				
	NO			0
	NC			1
<b>UL technical data</b>				
<b>Maximum UL/CSA horsepower ratings single-phase</b>				
	110V-120V	HP	0.5	
	220V-240V	HP	1.5	
<b>Maximum UL/CSA horsepower ratings three-phase, 3-pole</b>				
	200V-208V	HP	3	
	220V-240V	HP	3	
	440V-480V	HP	7.5	
	550V-600V	HP	10	
<b>Mechanical features</b>				
Terminals type				Clamp screw
Weight	g			394
<b>Dimensions</b>				

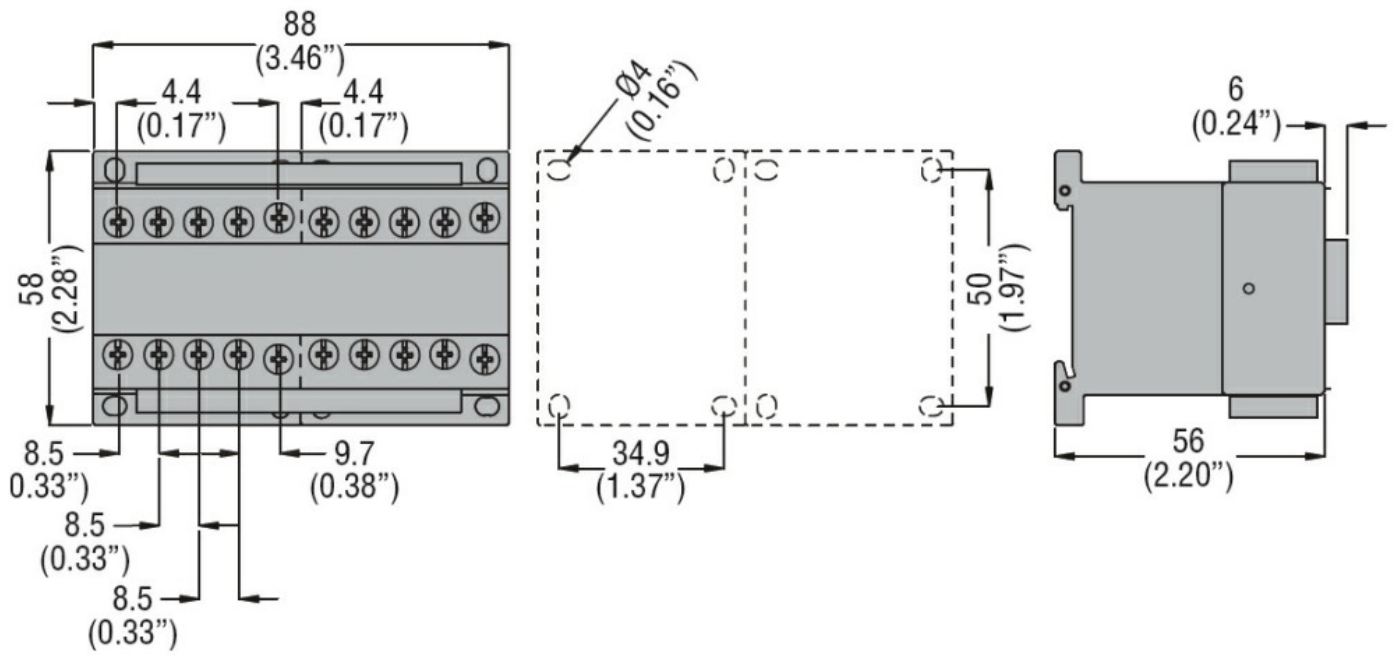

Wiring diagrams

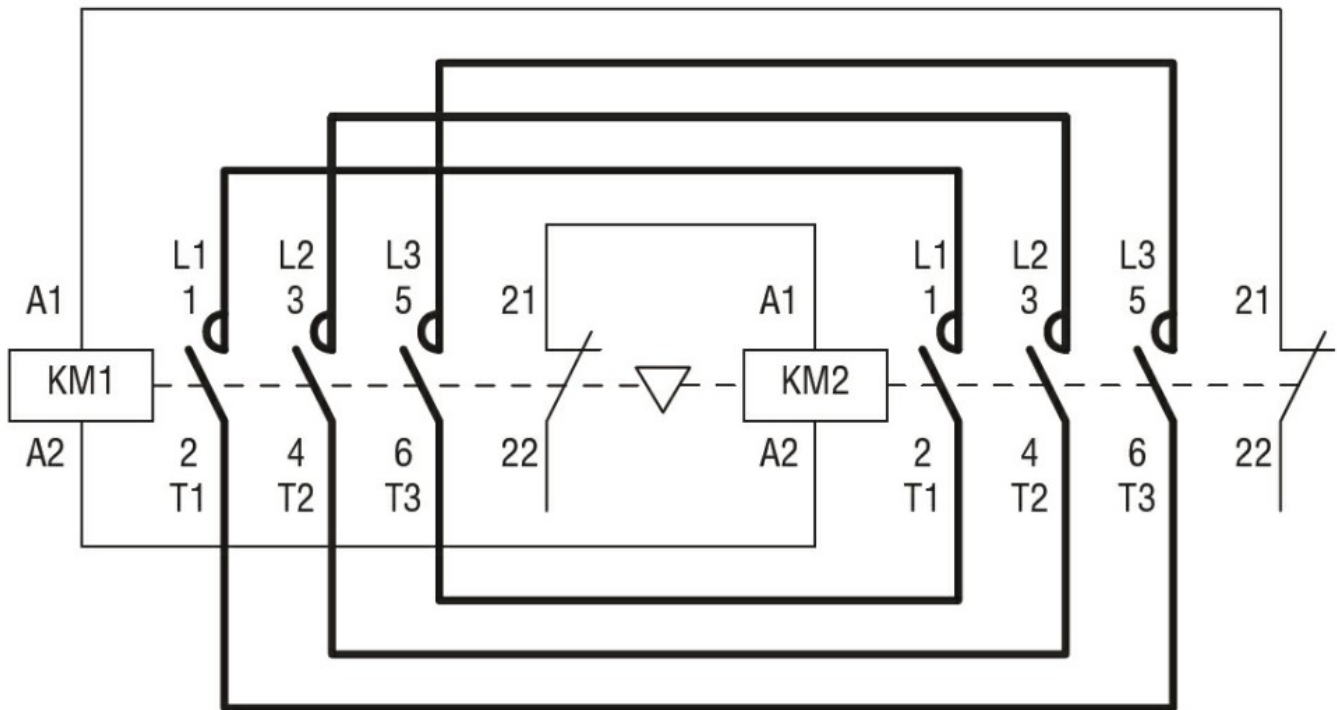

Certifications and compliance

Compliance

IEC/EN 60947-1  
IEC/EN 60947-4-1  
UL508 CSA C22.2 n° 14

Certificates

cULus

ETIM classification

ETIM 8.0

EC001037 -  
Motor  
starter/Motor  
starter  
combination