





Product designation				Reversing contactor
Product type designation				BGT09
Electrical features				
Maximum operating current ($\leq 440V$)			A	9
Contact characteristics				
Operational current Ie	AC-3 ($\leq 440V \leq 55^{\circ}C$)		A	9
Rated operational power AC-3 ($T \leq 55^{\circ}C$)				
	230V	kW	2.2	
	400V	kW	4	
	415V	kW	4.3	
	440V	kW	4.5	
	500V	kW	5	
	690V	kW	5	
Built-in auxiliary contacts				
	NO		1	
	NC		0	
UL technical data				
Maximum UL/CSA horsepower ratings single-phase				
	110V-120V	HP	0.5	
	220V-240V	HP	1.5	
Maximum UL/CSA horsepower ratings three-phase, 3-pole				
	200V-208V	HP	2	
	220V-240V	HP	3	
	440V-480V	HP	5	
	550V-600V	HP	5	
Mechanical features				
Terminals type				Clamp screw
Weight				g 380
Dimensions				

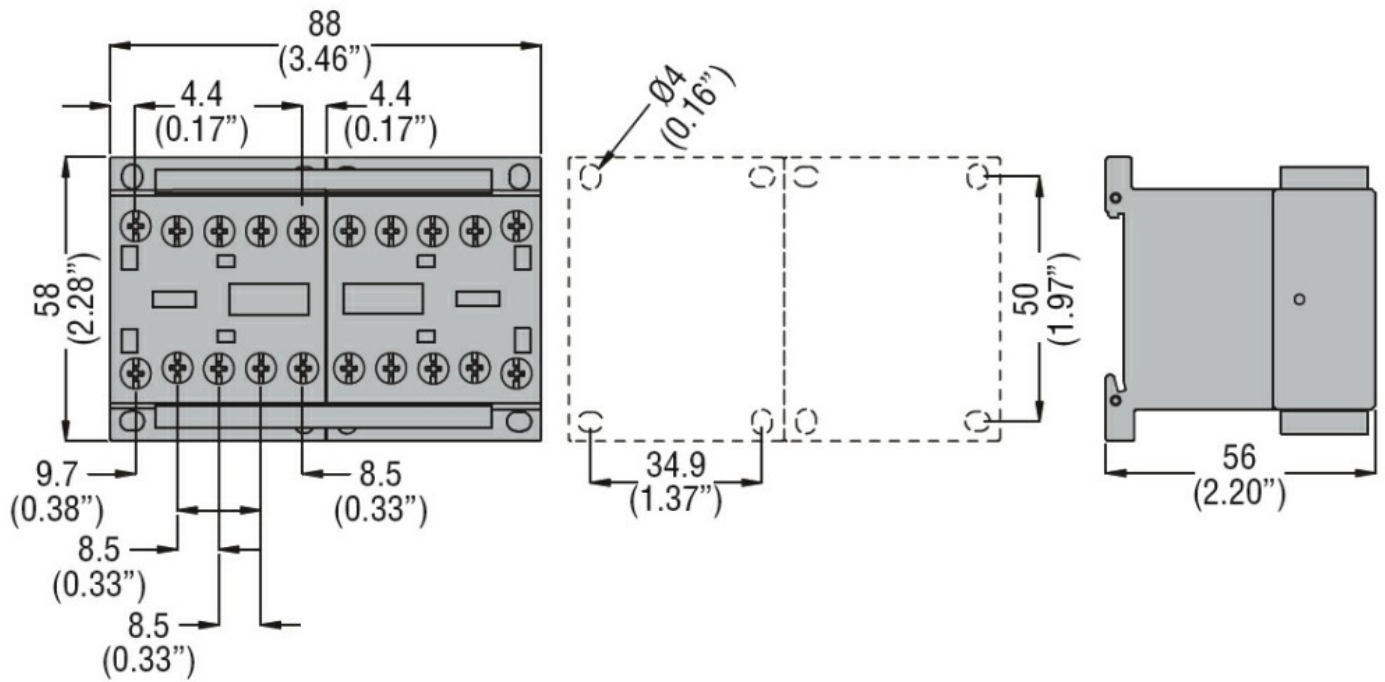

Wiring diagrams

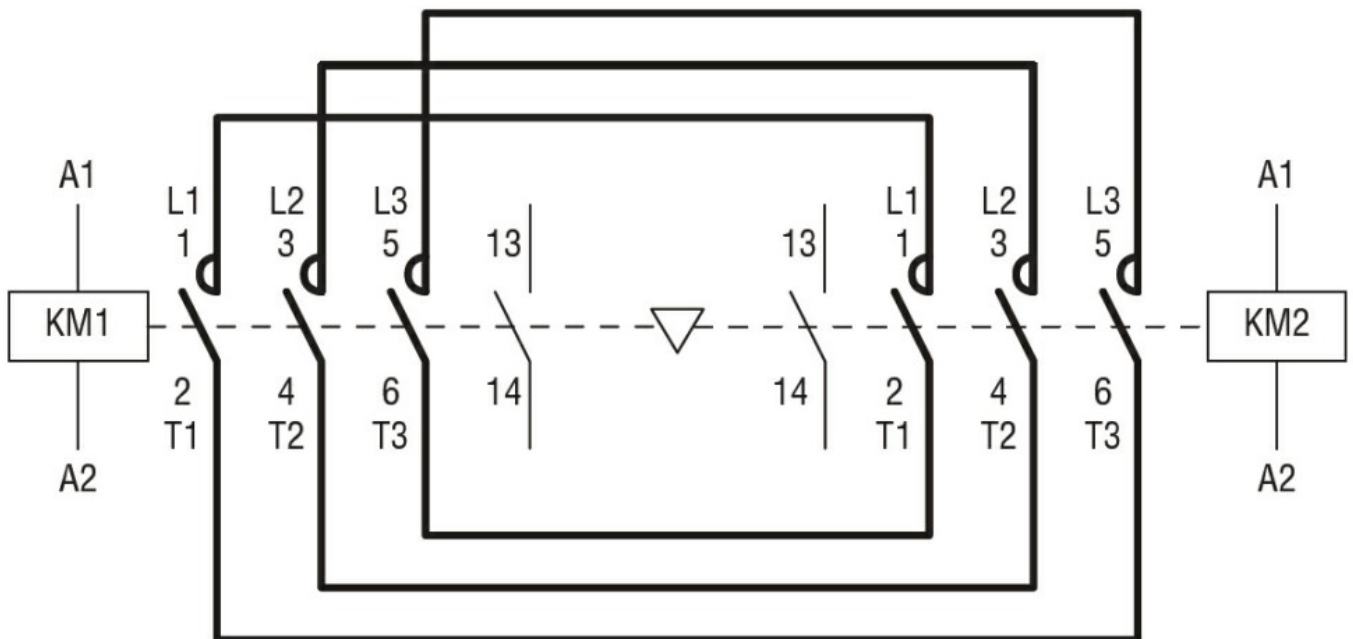

Certifications and compliance

Compliance

IEC/EN 60947-1
IEC/EN 60947-4-1
UL508 CSA C22.2 n° 14

Certificates

cULus

ETIM classification

ETIM 8.0

EC001037 -
Motor
starter/Motor
starter
combination

