





Product designation				Reversing contactor
Product type designation				BGT09
<b>Electrical features</b>				
Maximum operating current ( $\leq 440V$ )		A	9	
<b>Contact characteristics</b>				
Operational current Ie	AC-3 ( $\leq 440V \leq 55^{\circ}C$ )	A	9	
Rated operational power AC-3 ( $T \leq 55^{\circ}C$ )	230V	kW	2.2	
	400V	kW	4	
	415V	kW	4.3	
	440V	kW	4.5	
	500V	kW	5	
	690V	kW	5	
Built-in auxiliary contacts	NO		1	
	NC		0	
<b>UL technical data</b>				
Maximum UL/CSA horsepower ratings single-phase	110V-120V	HP	0.5	
	220V-240V	HP	1.5	
Maximum UL/CSA horsepower ratings three-phase, 3-pole	200V-208V	HP	2	
	220V-240V	HP	3	
	440V-480V	HP	5	
	550V-600V	HP	5	
<b>Mechanical features</b>				
Terminals type				Clamp screw
Weight				g 380
<b>Dimensions</b>				

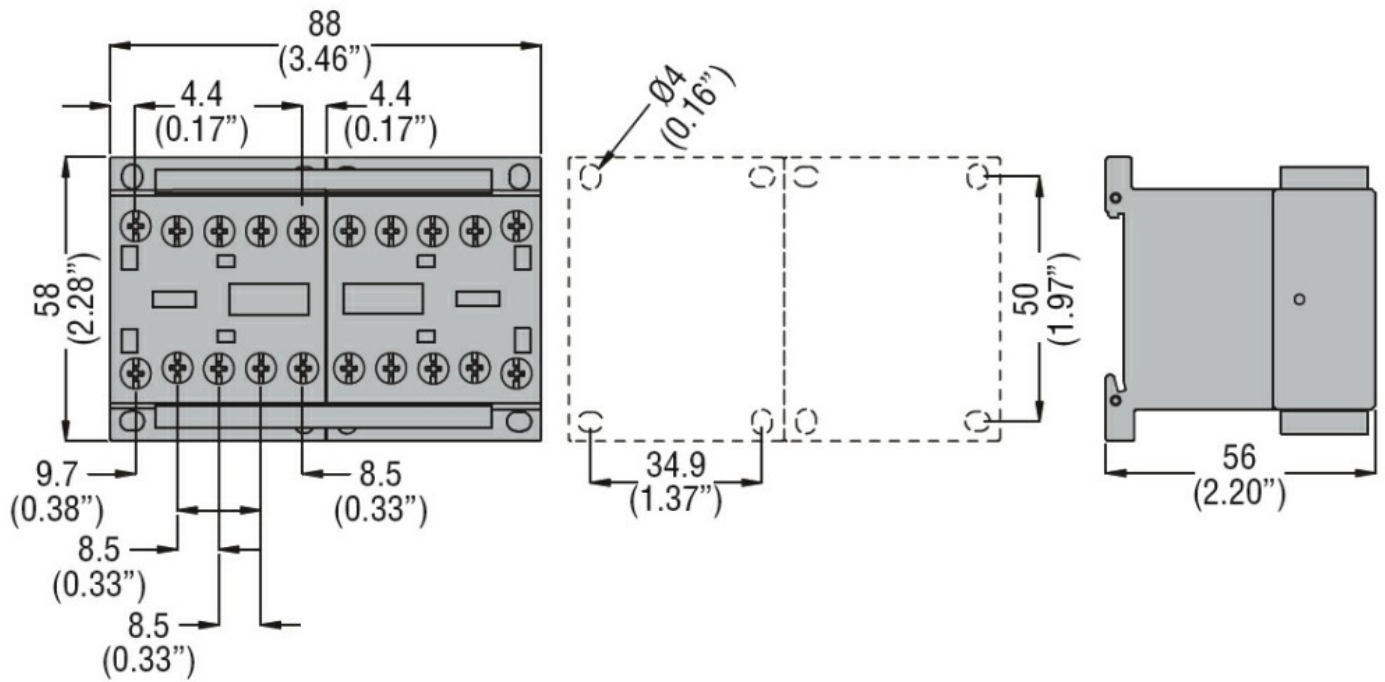

**Wiring diagrams**

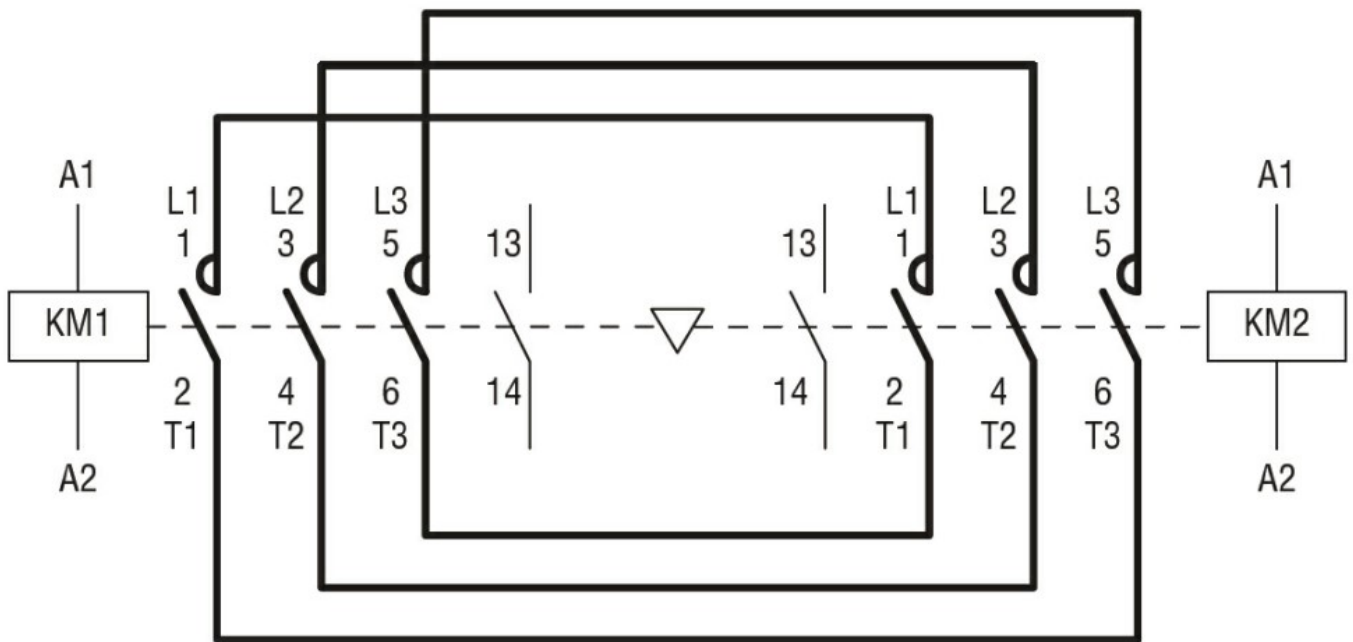

**Certifications and compliance**

**Compliance**

IEC/EN 60947-1  
 IEC/EN 60947-4-1  
 UL508 CSA C22.2 n° 14

**Certificates**

cULus

**ETIM classification**

ETIM 8.0

EC001037 -  
 Motor  
 starter/Motor  
 starter  
 combination

