




| | | | | |
|---|---------------------------------------|----|-----|---------------------|
| Product designation | | | | Reversing contactor |
| Product type designation | | | | BGT09 |
| Electrical features | | | | |
| Maximum operating current ($\leq 440V$) | | | A | 9 |
| Contact characteristics | | | | |
| Operational current Ie | AC-3 ($\leq 440V \leq 55^{\circ}C$) | | A | 9 |
| Rated operational power AC-3 ($T \leq 55^{\circ}C$) | 230V | kW | 2.2 | |
| | 400V | kW | 4 | |
| | 415V | kW | 4.3 | |
| | 440V | kW | 4.5 | |
| | 500V | kW | 5 | |
| | 690V | kW | 5 | |
| Built-in auxiliary contacts | | | NO | 1 |
| | | | NC | 0 |
| UL technical data | | | | |
| Maximum UL/CSA horsepower ratings single-phase | 110V-120V | HP | 0.5 | |
| | 220V-240V | HP | 1.5 | |
| Maximum UL/CSA horsepower ratings three-phase, 3-pole | 200V-208V | HP | 2 | |
| | 220V-240V | HP | 3 | |
| | 440V-480V | HP | 5 | |
| | 550V-600V | HP | 5 | |
| Mechanical features | | | | |
| Terminals type | | | | Clamp screw |
| Weight | | | | g 380 |
| Dimensions | | | | |

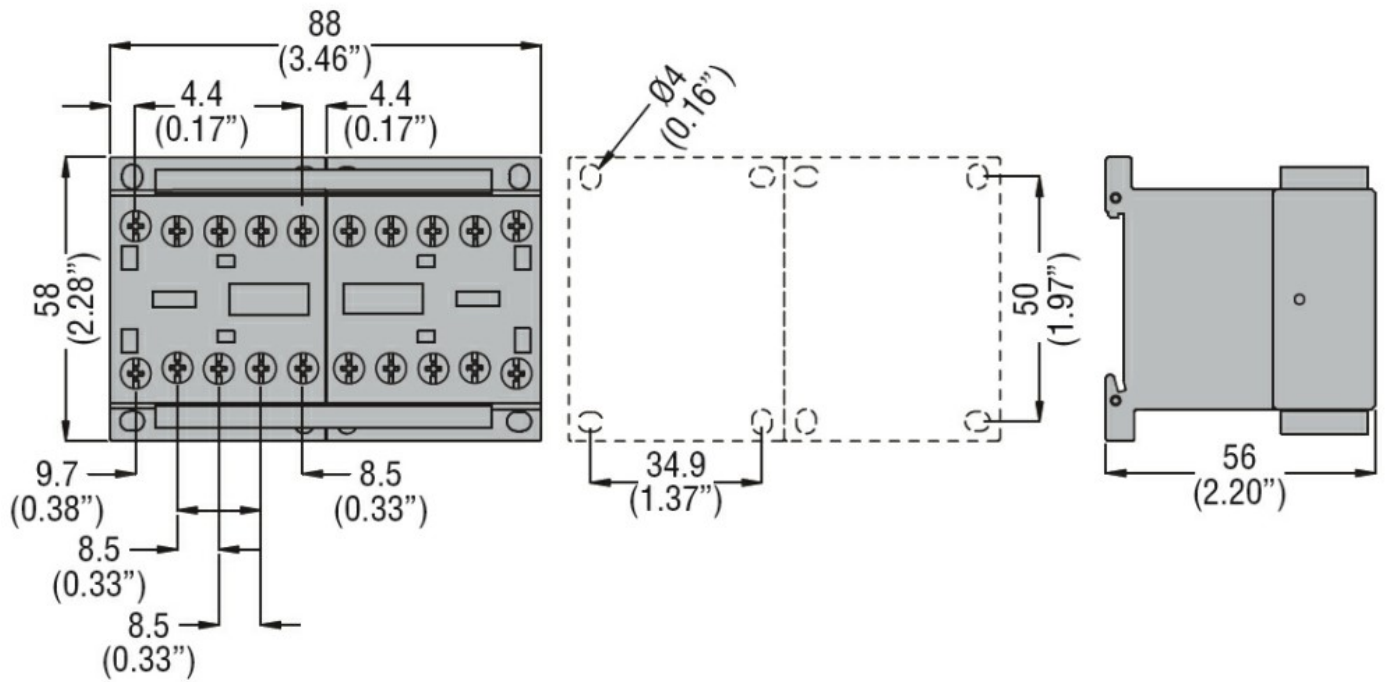

Wiring diagrams



Certifications and compliance

Compliance

IEC/EN 60947-1
 IEC/EN 60947-4-1
 UL508 CSA C22.2 n° 14

Certificates

cULus

ETIM classification

ETIM 8.0

EC001037 -
 Motor
 starter/Motor
 starter
 combination

