





Product designation	Reversing contactor		
Product type designation	BGT12		
<b>Electrical features</b>			
Maximum operating current ( $\leq 440V$ )	A	12	
<b>Contact characteristics</b>			
Operational current Ie	AC-3 ( $\leq 440V \leq 55^{\circ}C$ )	A	12
Rated operational power AC-3 ( $T \leq 55^{\circ}C$ )	230V	kW	3.2
	400V	kW	5.7
	415V	kW	6.2
	440V	kW	5.5
	500V	kW	5
	690V	kW	5
Built-in auxiliary contacts	NO	1	
	NC	0	
<b>UL technical data</b>			
Maximum UL/CSA horsepower ratings single-phase	110V-120V	HP	0.5
	220V-240V	HP	1.5
Maximum UL/CSA horsepower ratings three-phase, 3-pole	200V-208V	HP	3
	220V-240V	HP	3
	440V-480V	HP	7.5
	550V-600V	HP	10
<b>Mechanical features</b>			
Terminals type	Clamp screw		
Weight	g	380	
<b>Dimensions</b>			

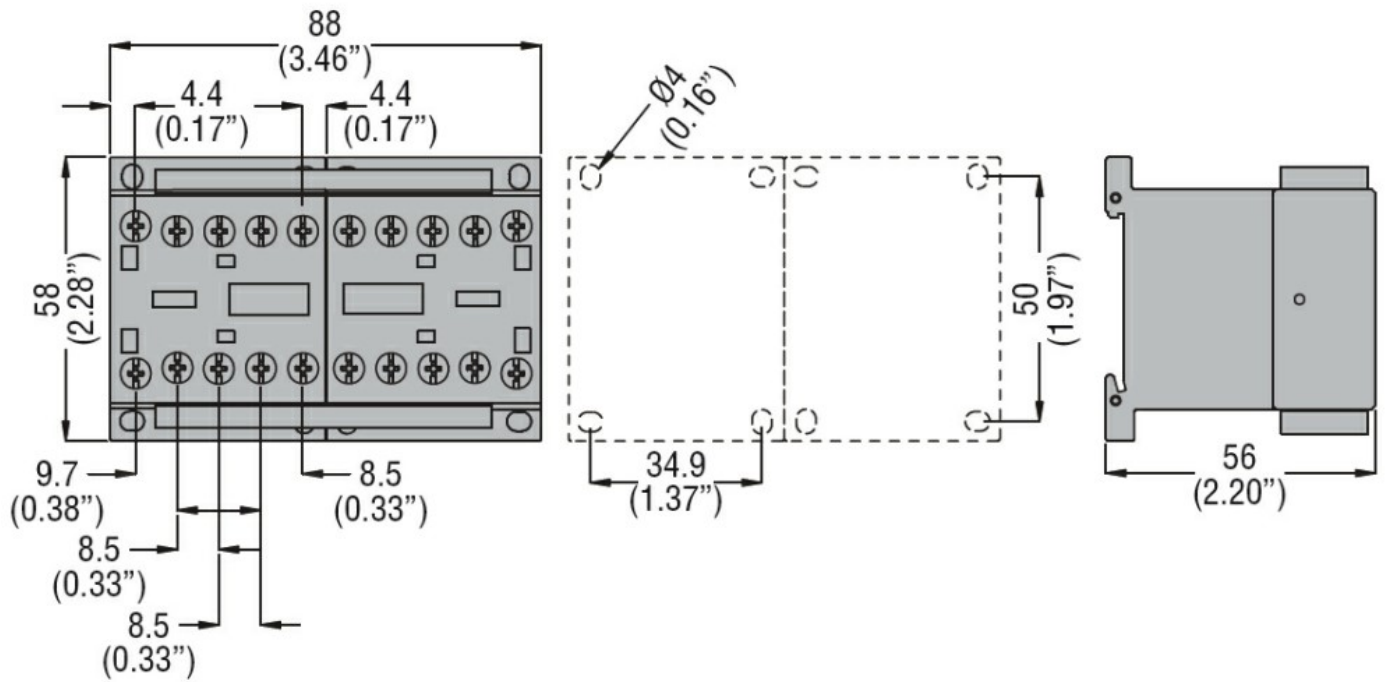

Wiring diagrams

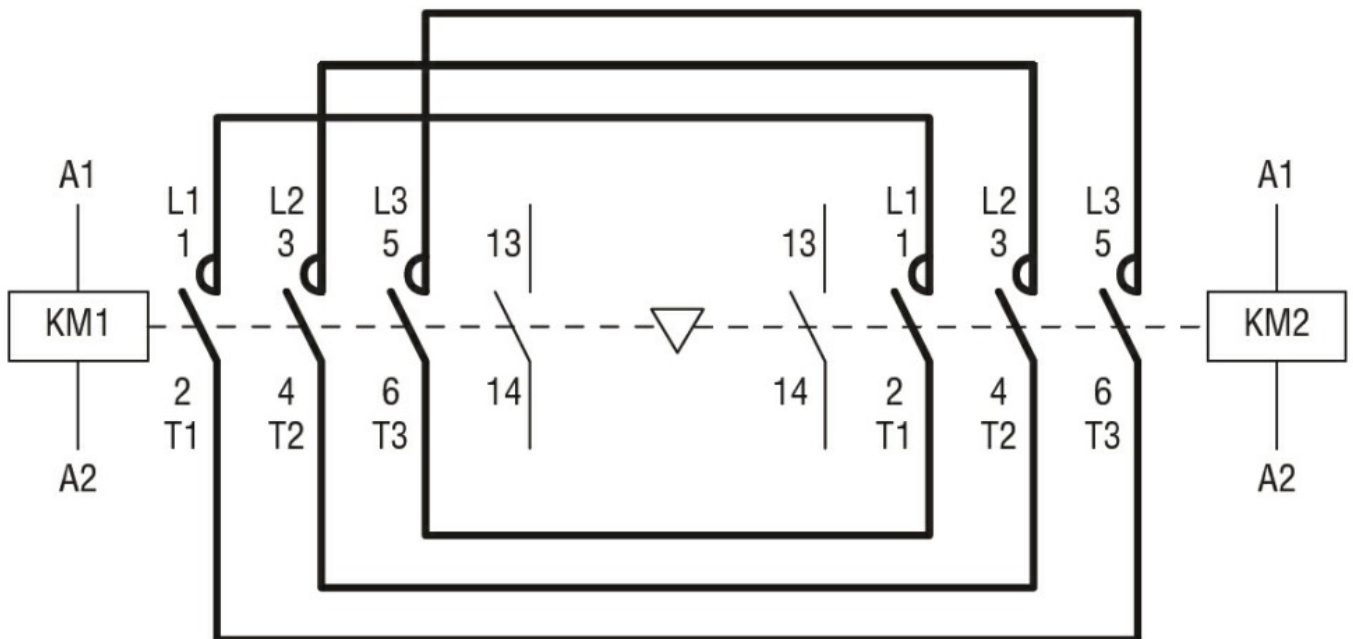

Certifications and compliance

Compliance

IEC/EN 60947-1  
 IEC/EN 60947-4-1  
 UL508 CSA C22.2 n° 14

Certificates

cULus

ETIM classification

ETIM 8.0

EC001037 -  
 Motor  
 starter/Motor  
 starter  
 combination

