





|   |                                       |     |     |
|---|---------------------------------------|-----|-----|
| Product designation                                   | Reversing contactor                   |     |     |
| Product type designation                              | BGT12                                 |     |     |
| <b>Electrical features</b>                            |                                       |     |     |
| Maximum operating current ( $\leq 440V$ )             | A                                     | 12  |     |
| <b>Contact characteristics</b>                        |                                       |     |     |
| Operational current Ie                                | AC-3 ( $\leq 440V \leq 55^{\circ}C$ ) | A   | 12  |
| Rated operational power AC-3 ( $T \leq 55^{\circ}C$ ) | 230V                                  | kW  | 3.2 |
|   | 400V                                  | kW  | 5.7 |
|   | 415V                                  | kW  | 6.2 |
|   | 440V                                  | kW  | 5.5 |
|   | 500V                                  | kW  | 5   |
|   | 690V                                  | kW  | 5   |
| Built-in auxiliary contacts                           | NO                                    | 1   |     |
|   | NC                                    | 0   |     |
| <b>UL technical data</b>                              |                                       |     |     |
| Maximum UL/CSA horsepower ratings single-phase        | 110V-120V                             | HP  | 0.5 |
|   | 220V-240V                             | HP  | 1.5 |
| Maximum UL/CSA horsepower ratings three-phase, 3-pole | 200V-208V                             | HP  | 3   |
|   | 220V-240V                             | HP  | 3   |
|   | 440V-480V                             | HP  | 7.5 |
|   | 550V-600V                             | HP  | 10  |
| <b>Mechanical features</b>                            |                                       |     |     |
| Terminals type  | Clamp screw                           |     |     |
| Weight  | g                                     | 380 |     |
| <b>Dimensions</b>                                     |                                       |     |     |

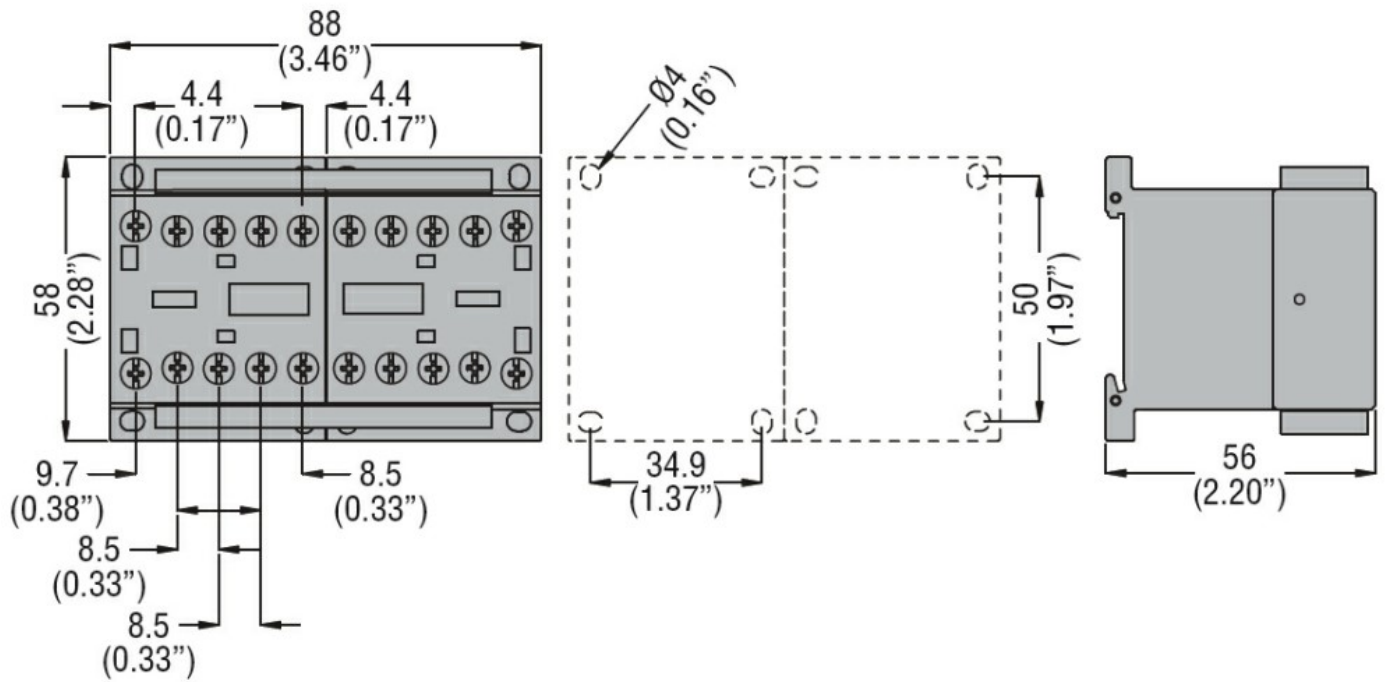

Wiring diagrams

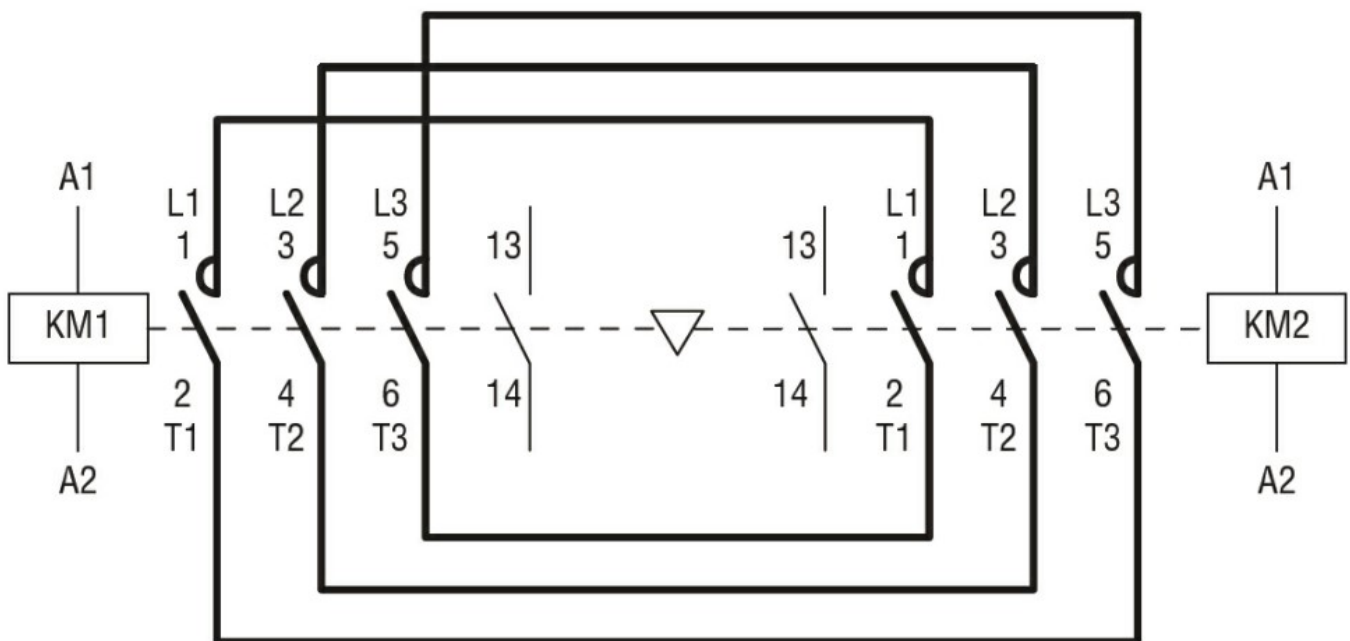

Certifications and compliance

Compliance

IEC/EN 60947-1  
IEC/EN 60947-4-1  
UL508 CSA C22.2 n° 14

Certificates

cULus

ETIM classification

ETIM 8.0

EC001037 -  
Motor  
starter/Motor  
starter  
combination

