



Reversing
contactor
BFA012

Product designation

Product type designation

Electrical features

Maximum operating current ($\leq 440V$) A 12

Contact characteristics

Operational current Ie AC-3 ($\leq 440V \leq 55^{\circ}C$) A 12

Rated operational power AC-3 ($T \leq 55^{\circ}C$)

230V	kW	3.2
400V	kW	5.7
415V	kW	6.2
440V	kW	6.2
500V	kW	7.5
690V	kW	10

Built-in auxiliary contacts

NO	0
NC	1

UL technical data

Maximum UL/CSA horsepower ratings single-phase

110V-120V	HP	1
220V-240V	HP	2

Maximum UL/CSA horsepower ratings three-phase, 3-pole


200V-208V	HP	5
220V-240V	HP	5
440V-480V	HP	7.5
550V-600V	HP	10

Mechanical features


Terminals type Clamp screw

Weight g 760

Dimensions

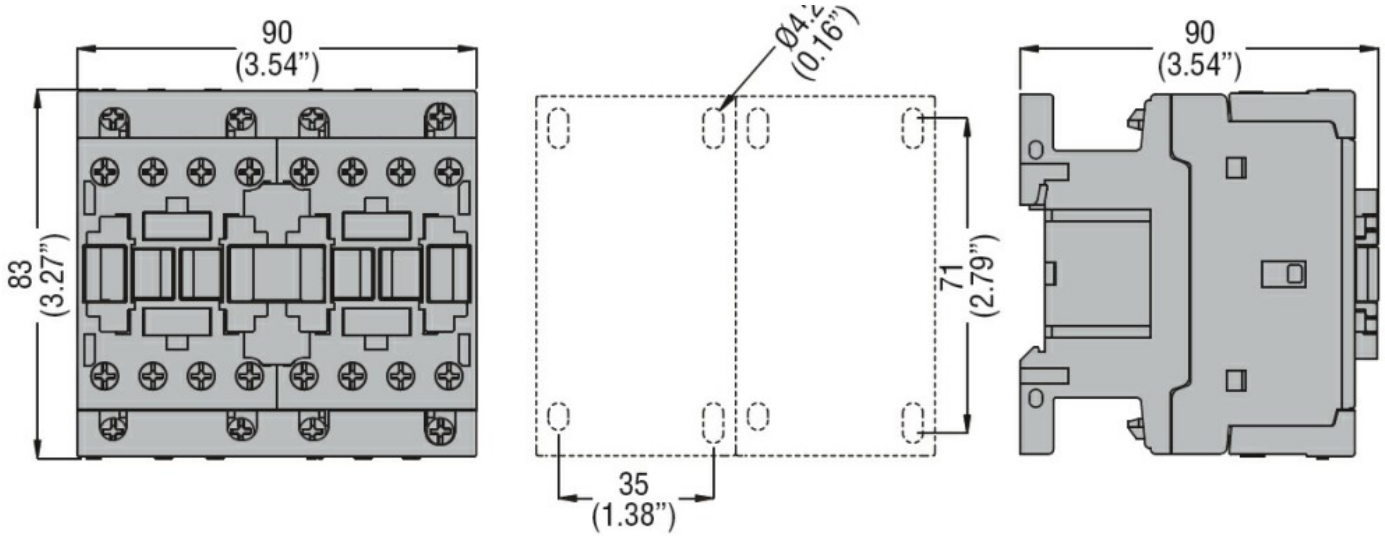

Wiring diagrams

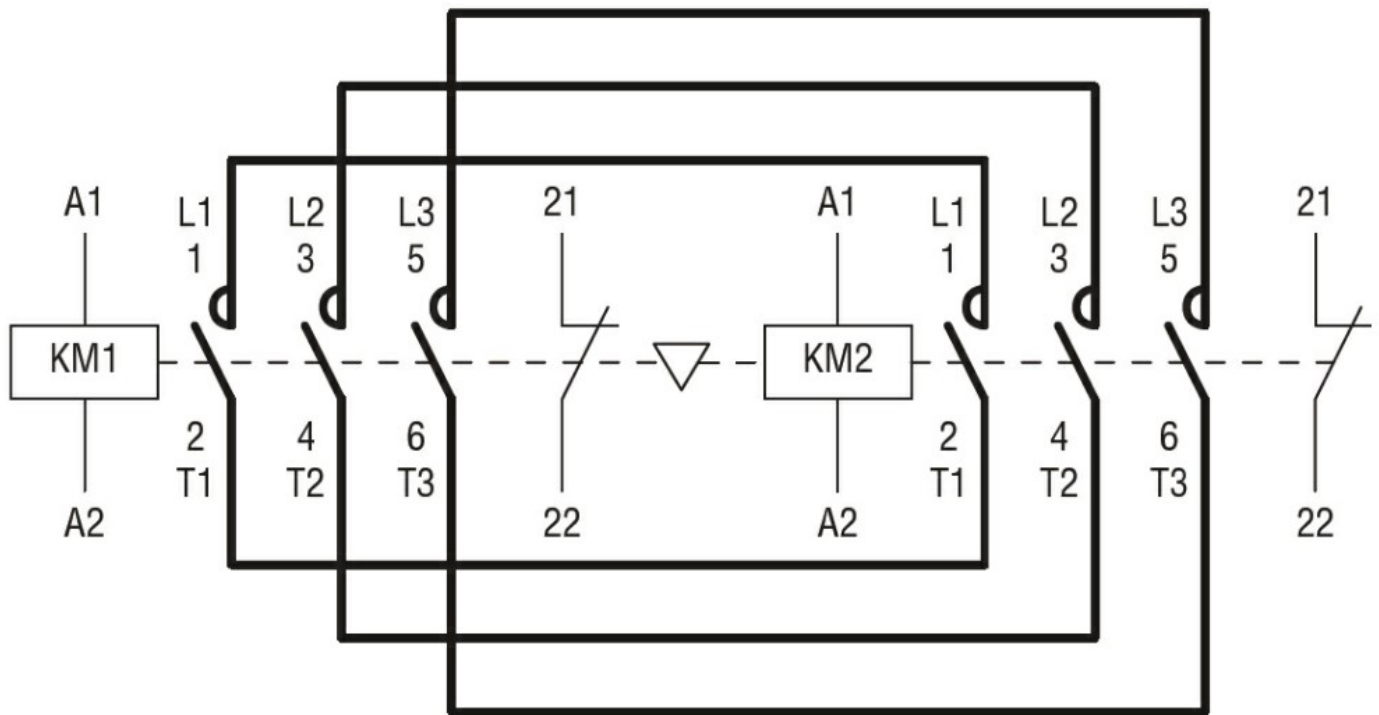

Certifications and compliance

Compliance

IEC/EN 60947-1
IEC/EN 60947-4-1
UL508 CSA C22.2 n° 14

Certificates

cULus

ETIM classification

ETIM 8.0

EC001037 -
Motor
starter/Motor
starter
combination