





Product designation				Reversing contactor
Product type designation				BFA018
Electrical features				
Maximum operating current ($\leq 440V$)		A	18	
Contact characteristics				
Operational current Ie		AC-3 ($\leq 440V \leq 55^{\circ}C$)	A	18
Rated operational power AC-3 ($T \leq 55^{\circ}C$)		230V	kW	4
		400V	kW	7.5
		415V	kW	9
		440V	kW	9
		500V	kW	10
		690V	kW	10
Built-in auxiliary contacts		NO	0	
		NC	1	
UL technical data				
Maximum UL/CSA horsepower ratings single-phase		110V-120V	HP	1
		220V-240V	HP	3
Maximum UL/CSA horsepower ratings three-phase, 3-pole		200V-208V	HP	5
		220V-240V	HP	5
		440V-480V	HP	10
		550V-600V	HP	15
Mechanical features				
Terminals type				Clamp screw
Weight				g 760
Dimensions				

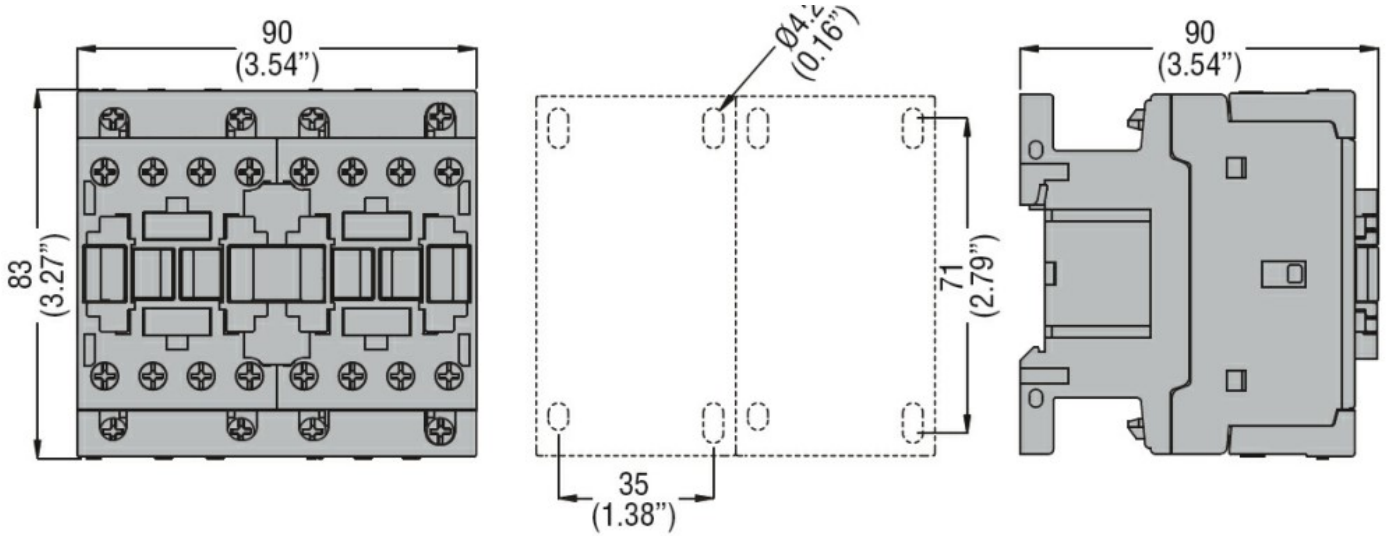

Wiring diagrams

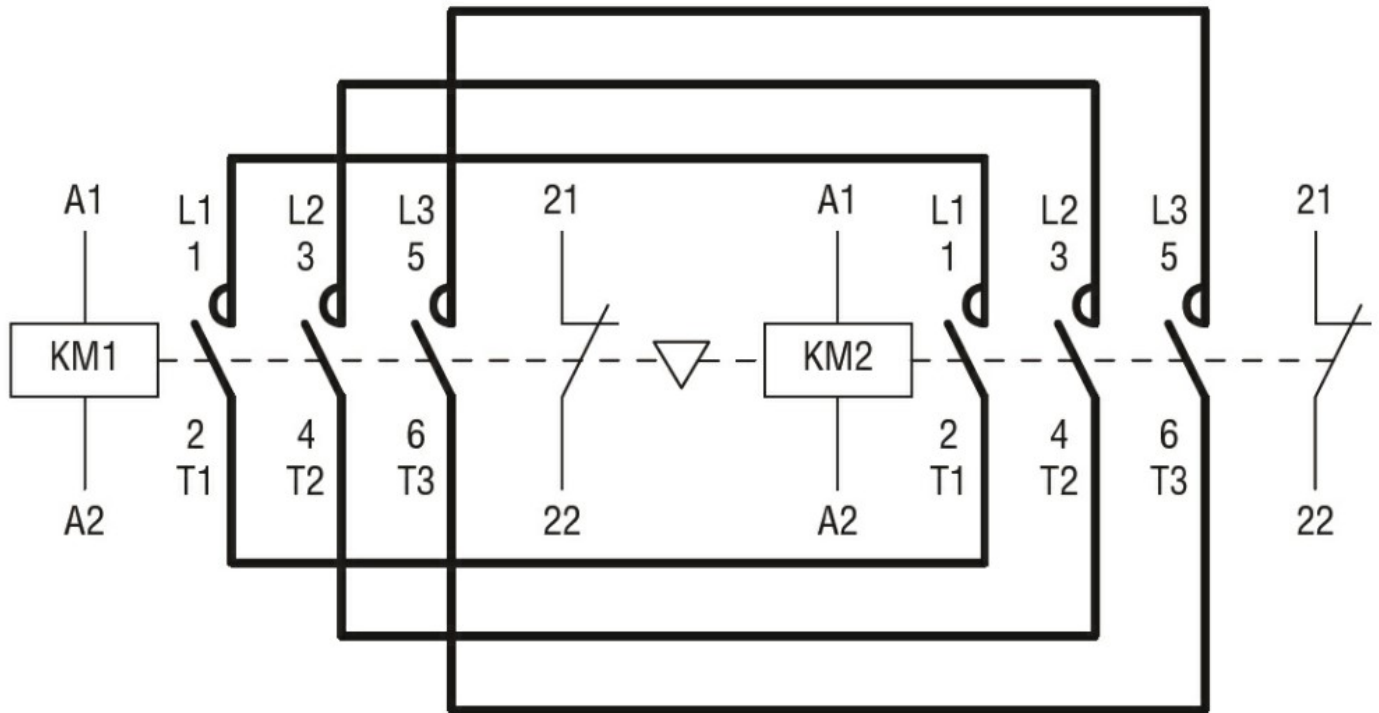

Certifications and compliance

Compliance

IEC/EN 60947-1
IEC/EN 60947-4-1
UL508 CSA C22.2 n° 14

Certificates

cULus

ETIM classification

ETIM 8.0

EC001037 -
Motor
starter/Motor
starter
combination