





Product designation				Reversing contactor
Product type designation				BFA018
<b>Electrical features</b>				
Maximum operating current ( $\leq 440V$ )		A	18	
<b>Contact characteristics</b>				
Operational current Ie		AC-3 ( $\leq 440V \leq 55^{\circ}C$ )	A	18
Rated operational power AC-3 ( $T \leq 55^{\circ}C$ )		230V	kW	4
		400V	kW	7.5
		415V	kW	9
		440V	kW	9
		500V	kW	10
		690V	kW	10
Built-in auxiliary contacts		NO	0	
		NC	1	
<b>UL technical data</b>				
Maximum UL/CSA horsepower ratings single-phase		110V-120V	HP	1
		220V-240V	HP	3
Maximum UL/CSA horsepower ratings three-phase, 3-pole		200V-208V	HP	5
		220V-240V	HP	5
		440V-480V	HP	10
		550V-600V	HP	15
<b>Mechanical features</b>				
Terminals type				Clamp screw
Weight			g	760
<b>Dimensions</b>				

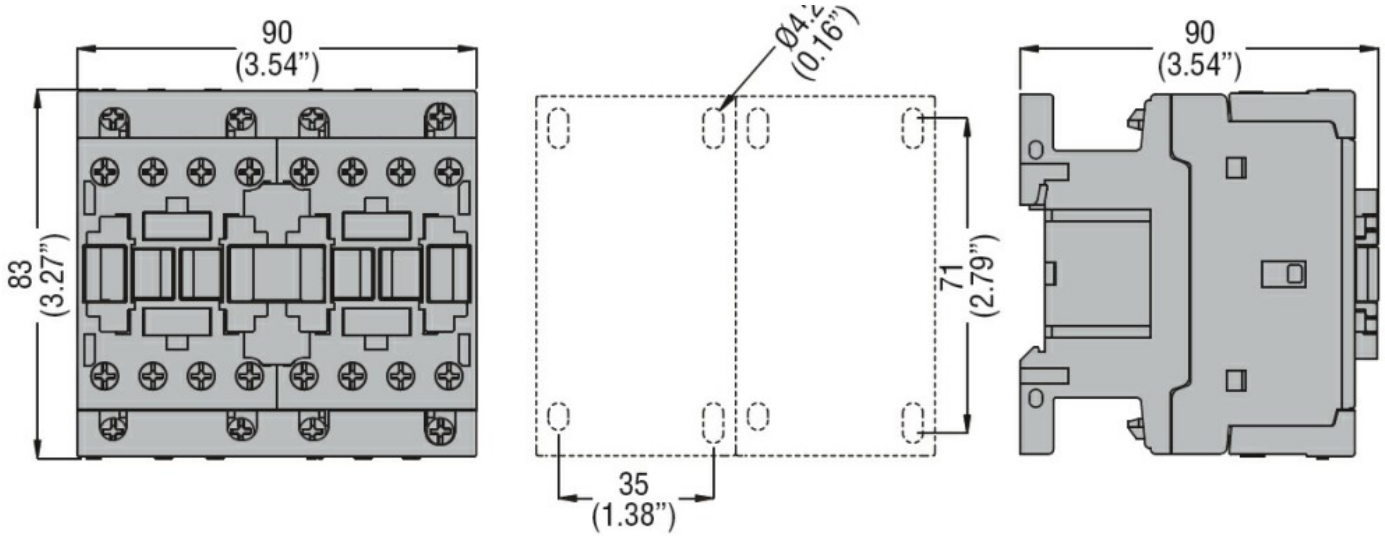

**Wiring diagrams**

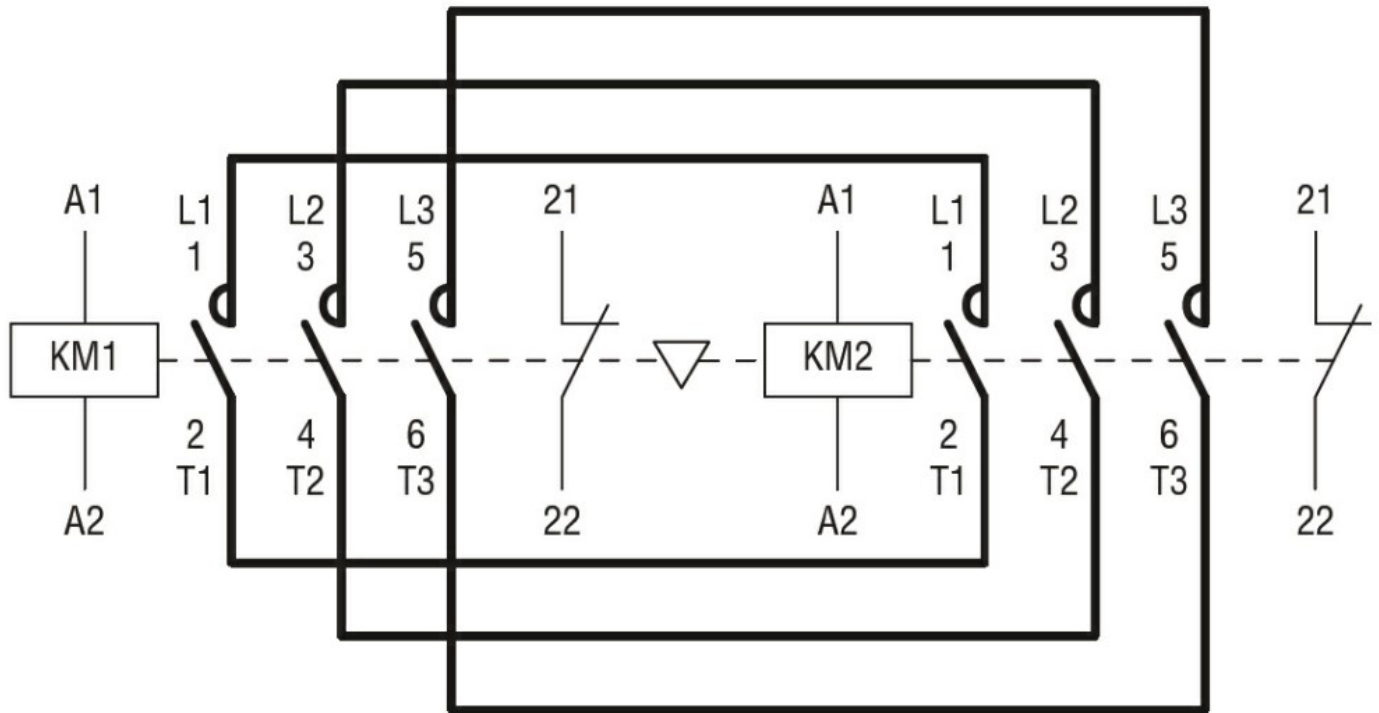

**Certifications and compliance**

**Compliance**

IEC/EN 60947-1  
IEC/EN 60947-4-1  
UL508 CSA C22.2 n° 14

**Certificates**

cULus

**ETIM classification**

ETIM 8.0

EC001037 -  
Motor  
starter/Motor  
starter  
combination