




|   |                        |       |     |
|---|------------------------|-------|-----|
| Product designation                                   | Direct-on-line starter |       |     |
| Product type designation                              | M2P02512...B3          |       |     |
| <b>Electrical features</b>                            |                        |       |     |
| Relay adj range                                       | A                      | 20-25 |     |
| IEC technical characteristics (≤440V)                 |                        |       |     |
|   | le                     | A     | 25  |
|   | kW                     | kW    | 11  |
| <b>Components</b>                                     |                        |       |     |
| Starter enclosure standard supplied                   | M2PA                   |       |     |
| Contactors standard supplied                          | BF2510A                |       |     |
| Thermal relay standard supplied                       | RF382500               |       |     |
| <b>UL technical data</b>                              |                        |       |     |
| Maximum UL/CSA horsepower ratings single-phase        |                        |       |     |
|   | 110V-120V              | HP    | 2   |
|   | 220V-240V              | HP    | 3   |
| Maximum UL/CSA horsepower ratings three-phase, 3-pole |                        |       |     |
|   | 200V-208V              | HP    | 7.5 |
|   | 220V-240V              | HP    | 7.5 |
|   | 440V-480V              | HP    | 15  |
|   | 550V-600V              | HP    | 15  |
| <b>Mechanical features</b>                            |                        |       |     |
| Weight  | g                      | 1220  |     |
| <b>Ambient conditions</b>                             |                        |       |     |
| Operating temperature                                 |                        |       |     |
|   | min                    | °C    | -25 |
|   | max                    | °C    | +60 |
| Storage temperature                                   |                        |       |     |
|   | min                    | °C    | -40 |
|   | max                    | °C    | +70 |
| <b>Resistance &amp; Protection</b>                    |                        |       |     |
| Frontal IP degree                                     | IP65                   |       |     |
| <b>Dimensions</b>                                     |                        |       |     |

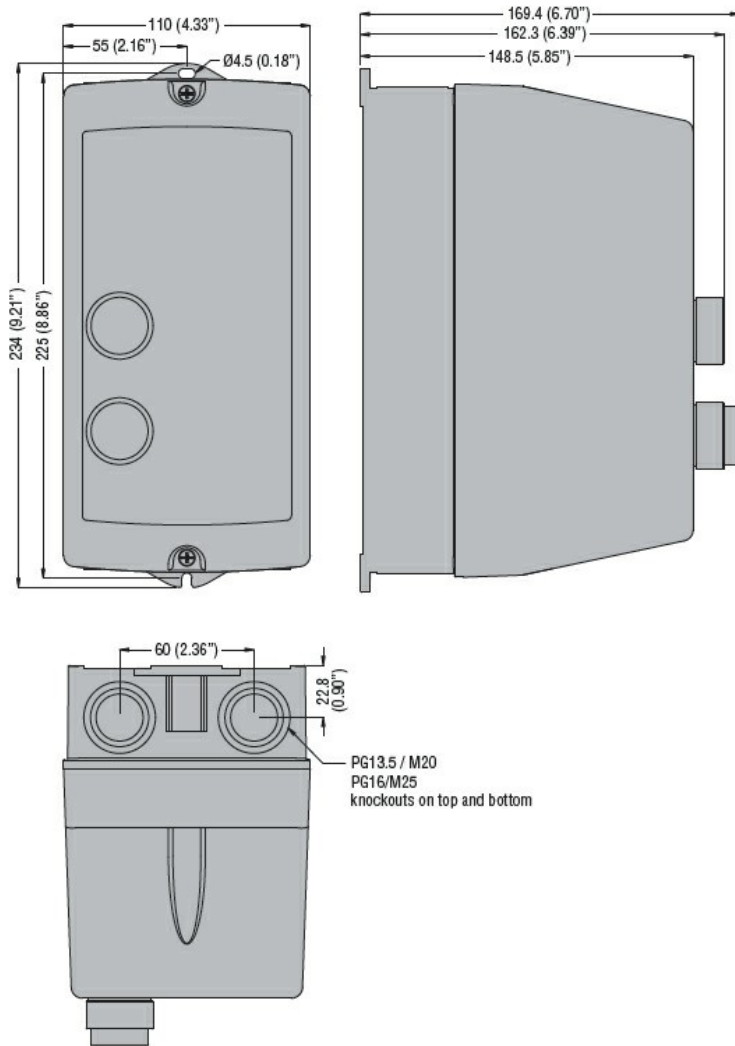

Wiring diagrams



I = Start; O = Stop/Reset

**Certifications and compliance**

Compliance

IEC/EN 60947-1  
IEC/EN 60947-4-1  
UL508 CSA C22.2 n° 14

Certificates

CSAus  
cULus  
EAC

**ETIM classification**

ETIM 8.0

EC001037 -  
Motor  
starter/Motor  
starter  
combination