




Product designation	Empty enclosures	
Product type designation	M3N	
Electrical features		
Maximum operating current ($\leq 440V$)	A	80
Components		
Contactor standard supplied	BF40A, BF50A, BF65A, BF80A, BF94A	
Thermal relay to purchase separately	RF82	
Mechanical features		
Weight	g	1800
Ambient conditions		
Operating temperature	min °C	-25
	max °C	+60
Storage temperature	min °C	-40
	max °C	+70

Resistance & Protection		
Frontal IP degree	IP65	

Dimensions

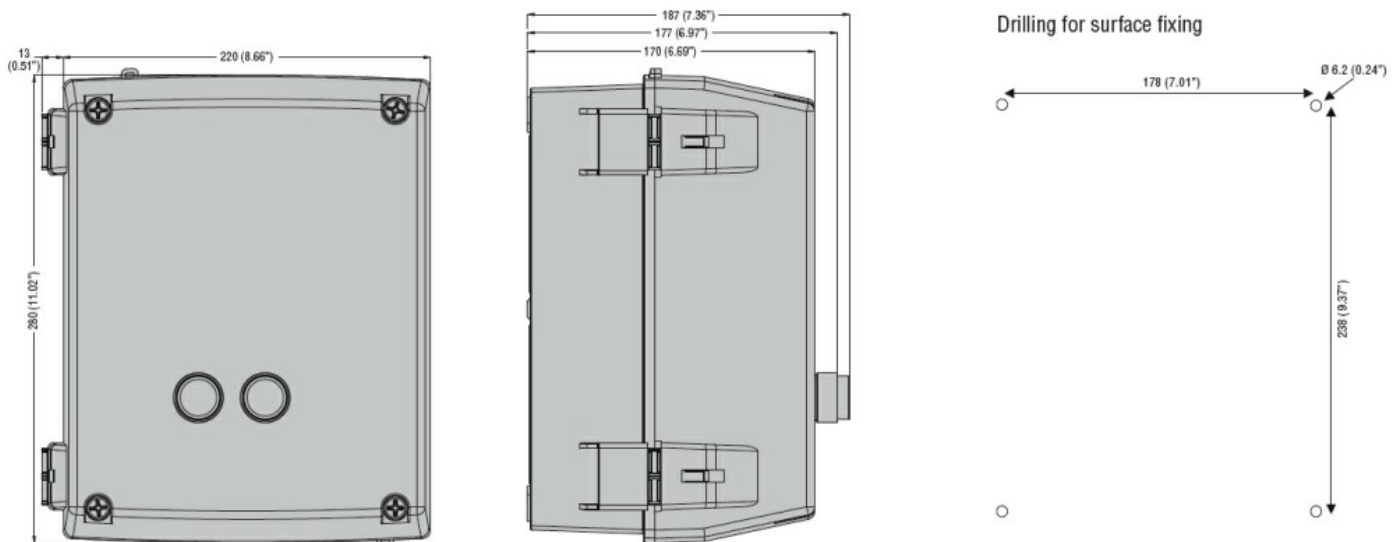

Certifications and compliance	
Compliance	IEC/EN 60947-1
	IEC/EN 60947-4-1

Certificates	cULus
--------------	-------

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices