





Product designation	Empty enclosures	
Product type designation	M3PA	
Electrical features		
Maximum operating current ($\leq 440V$)	A	80
Components		
Contactor standard supplied	BF40A, BF50A, BF65A, BF80A, BF94A	
Thermal relay to purchase separately	RF82	
Mechanical features		
Weight	g	1900
Ambient conditions		
Operating temperature	min	°C -25
	max	°C +60
Storage temperature	min	°C -40
	max	°C +70

Resistance & Protection		
Frontal IP degree	IP65	

Dimensions

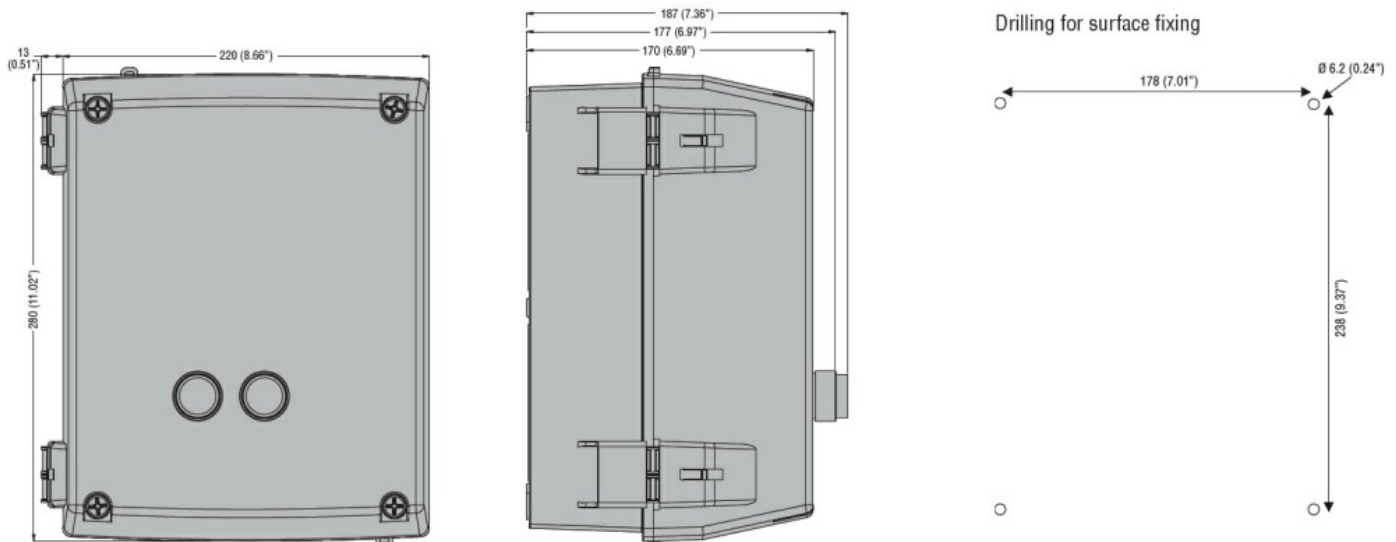

Wiring diagrams

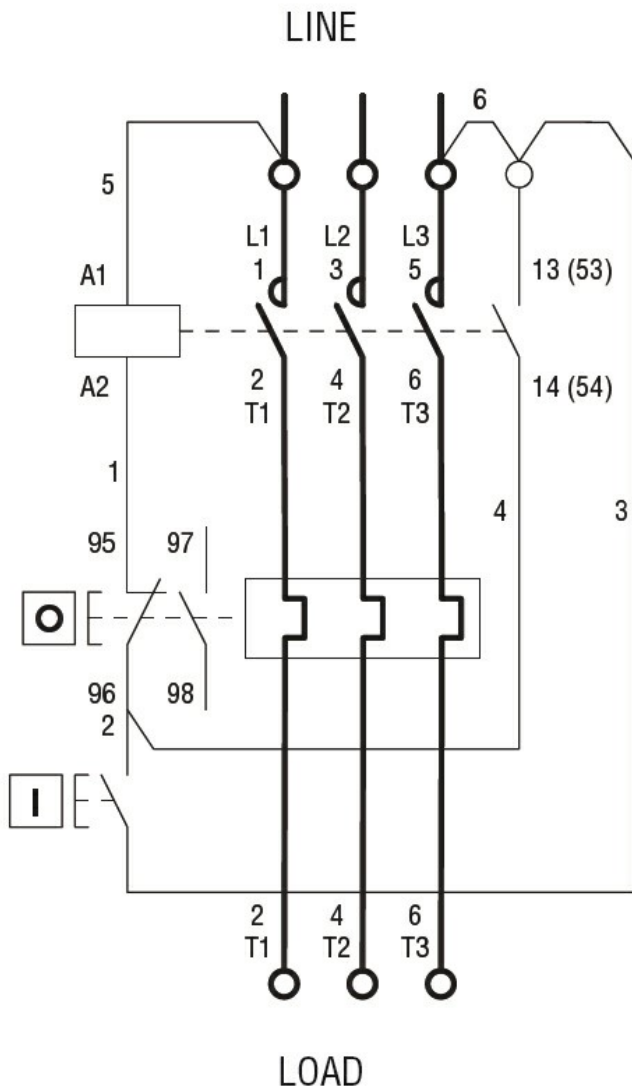

I = Start; O = Stop/Reset

Certifications and compliance

Compliance

- CSA C22.2 n° 14
- IEC/EN 60947-1
- IEC/EN 60947-4-1
- UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices