



Product designation SOCKET  
Product type designation HR5XS21

**Contact characteristics**

Rated insulation voltage $U_i$ IEC/EN	V	250
Rated impulse withstand voltage $U_{imp}$	kV	4

**Mechanical features**

Socket screw tightening tool (cross / flat blade) Phillips 1/4.5mm

Conductor section

AWG/Kcmil


min	20
max	14

IEC

min	mm <sup>2</sup>	0.5
max	mm <sup>2</sup>	2.5


Fixing DIN rail or with screws

**Dimensions**

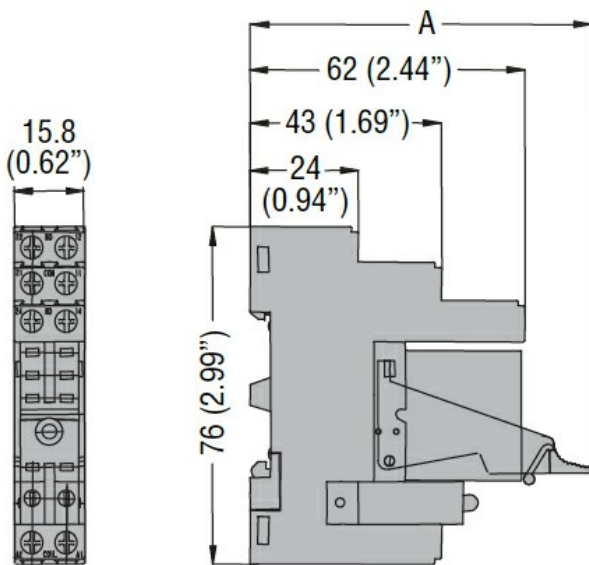

A: 65mm (2.56") con HR3X88  
75mm (2.95") con XR5X88

**Wiring diagrams**

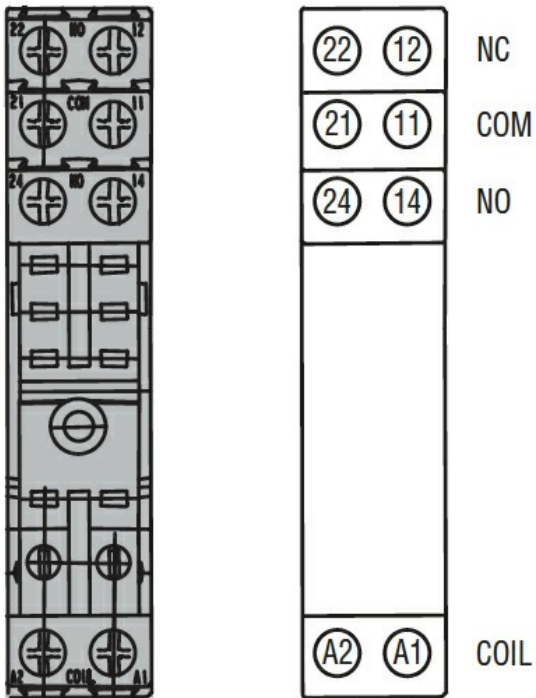

**Certifications and compliance**

Compliance

IEC/EN 61810

Certificates

CSA

cURus

EAC

**ETIM classification**

ETIM 8.0

EC001456 -  
Relay socket