



Product designation	Bell
Product type designation	CBE
Operating voltage type	AC
Number of DIN modules	1

Electrical features

Power consumption	VA	5
Supply voltage	VAC	12
Sound intensity	dB	84

Control circuit

Auxiliary rated supply voltage U_s	12VAC
--------------------------------------	-------

Ambient conditions

Operating temperature	min	°C	-10
	max	°C	+55

Storage temperature	min	°C	-40
	max	°C	+80

Mechanical features


Tightening torque for terminals	max	Nm	0.5
---------------------------------	-----	----	-----

Conductor section	Power terminal	min	mm ²	0.5
		max	mm ²	1.5


Terminals tool	M3
----------------	----

Weight	g	70
--------	---	----

Dimensions

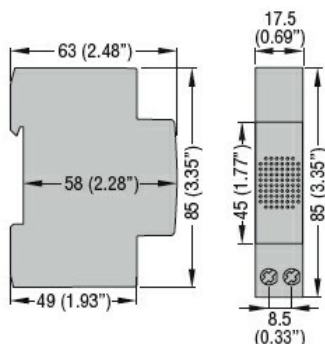

Wiring diagrams

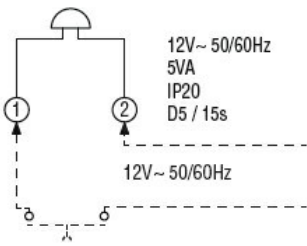

Certifications and compliance

Compliance

IEC/EN 62080

ETIM classification

ETIM 8.0

EC001026 -
Acoustic indicator