



Product designation	Buzzer
Product type designation	CBZ
Operating voltage type	AC
Number of DIN modules	1

#### Electrical features

Power consumption	VA	10
Supply voltage	VAC	230
Sound intensity	dB	80

#### Control circuit

Auxiliary rated supply voltage $U_s$	230VAC
--------------------------------------	--------

#### Ambient conditions

Operating temperature	min	°C	-10
	max	°C	+55
Storage temperature	min	°C	-40
	max	°C	+80

#### Mechanical features

Tightening torque for terminals	max	Nm	0.5
---------------------------------	-----	----	-----

#### Conductor section

Power terminal

min	mm <sup>2</sup>	0.5
max	mm <sup>2</sup>	1.5


#### Terminals tool

M3


#### Weight

g 63

#### Dimensions

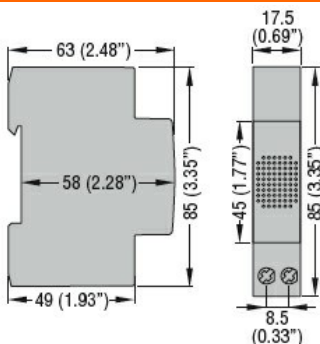

#### Wiring diagrams

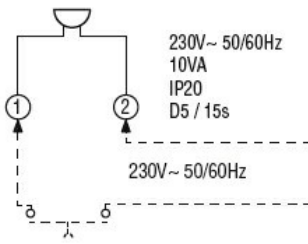

### Certifications and compliance

#### Compliance

IEC/EN 62080

### ETIM classification

ETIM 8.0

EC000844 -  
Buzzer