



Product designation

Product type designation

Operating voltage type

Number of DIN modules

Bell/Buzzer
transformer
CTRB
AC
2

Electrical features

Power consumption	VA	10
Supply voltage	VAC	230
Rated output voltage	VAC	12

Control circuit

Auxiliary rated supply voltage U_s	230VAC
--------------------------------------	--------

Ambient conditions

Operating temperature	min	°C	-10
	max	°C	+40

Storage temperature	min	°C	-40
	max	°C	+80

Mechanical features


Tightening torque for terminals	max	Nm	0.5
---------------------------------	-----	----	-----

Conductor section	Power terminal	min	mm ²	0.5
		max	mm ²	1.5


Terminals tool	M3
----------------	----

Weight	g	339
--------	---	-----

Dimensions

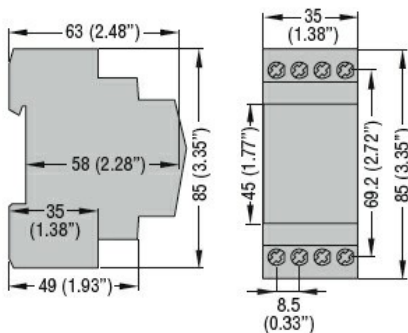

Wiring diagrams

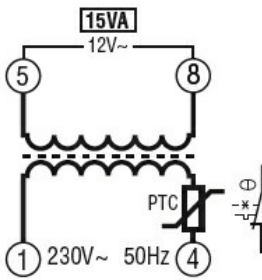

Certifications and compliance

Compliance

IEC/EN 62080

ETIM classification

ETIM 8.0

EC001547 - Bell
transformer