



Product designation

Safety transformer

Product type designation

CTRS

Operating voltage type

AC

Number of DIN modules

3

Electrical features

Output power	VA	25
Supply voltage	VAC	230
Rated output voltage	VAC	12...24

Control circuit

Auxiliary rated supply voltage U_s	230VAC
--------------------------------------	--------

Ambient conditions

Operating temperature	min	°C	-10
	max	°C	+25

Storage temperature

min	°C	-40
max	°C	+70

Mechanical features

Tightening torque for terminals	max	Nm	1
---------------------------------	-----	----	---

Conductor section

Power terminal	min	mm ²	0.5
	max	mm ²	10


Terminals tool

M4


Weight

g 582

Dimensions

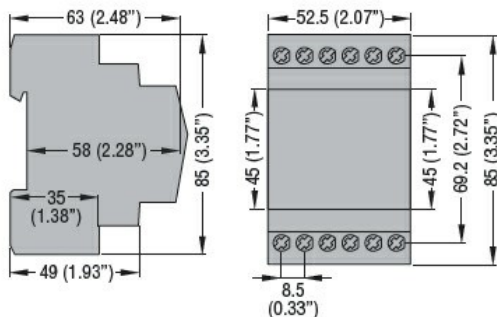

Wiring diagrams

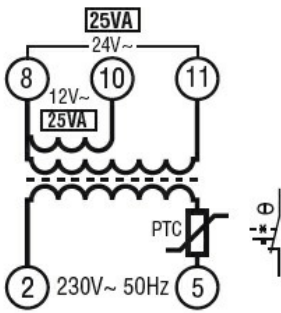

Certifications and compliance

Compliance

IEC/EN 61558-2-8

ETIM classification

ETIM 8.0

EC002486 -
 One-phase
 control
 transformer