



Product designation  
Product type designation

Description

Accessories for

Motor operator  
P5X193D024  
Motor operator  
for remote  
operation.  
Accessories for  
IEC-compliant  
MCCBs

#### Operational characteristics

Rated operational voltage	V	24VDC
Rated current (I <sub>n</sub> )	A	≤5A
Mechanical operation	cycles/h	20
Average closing time	ms	700
Average opening time	ms	420
Power consumption	W	35


#### Mechanical features


Weight	g	3500
--------	---	------

#### Operations

Mechanical life	cycles	10000
-----------------	--------	-------

#### Dimensions

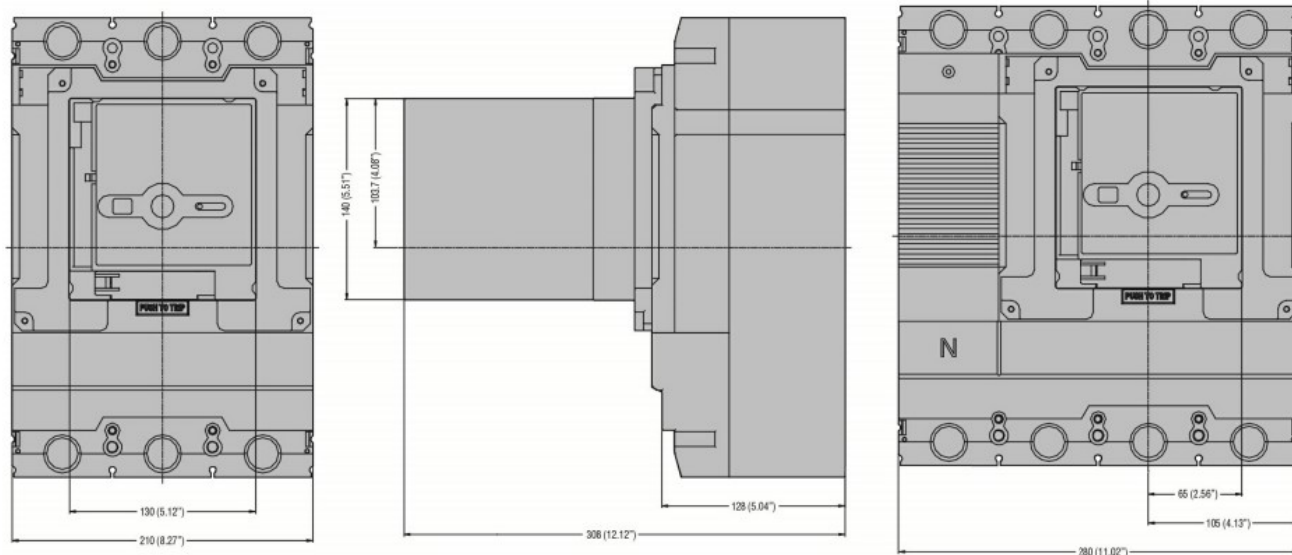

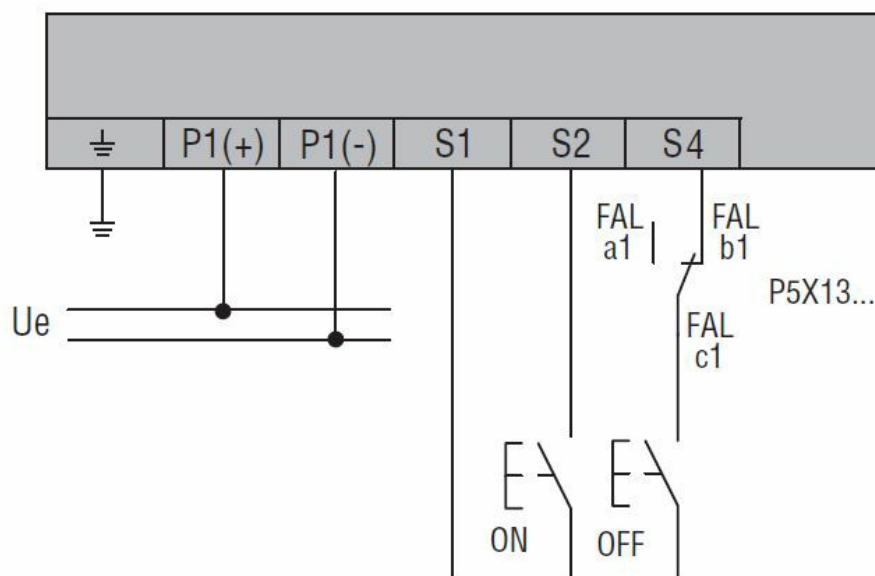

**Note:** Connect an NC contact of an alarm switch contact block in series with S4 to prevent remote closing of the MCCB after tripping due to overcurrent or short circuit.

Wiring diagrams

Certifications and compliance

Certificates

ETIM classification

EC000066 - Power contactor, AC switching