



Product designation

RJ45 interface,
Ethernet
connection type
LPCD0
Cat.5E

Product type designation

Transmission characteristics

General characteristics

Material

Polyamide

IEC degree of protection

IP65 on front and
IP20 on rear

Electrical characteristics

Rated insulation voltage U_i IEC/EN

V 24VAC

Contact resistance

mΩ ≤40

Mechanical features

Weight

g 26

UL technical data

UL degree of protection

1, 2, 3R, 4, 4X,
12, 12K on front

Ambient conditions

Temperature


Operating temperature

min °C -25
max °C +70

Storage temperature

min °C -40
max °C +85

Dimensions

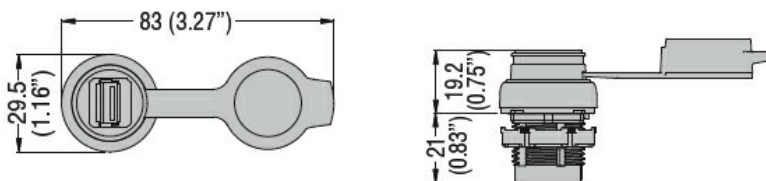

Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN/BS 60947-1

IEC/EN/BS 60947-5-1

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC002780 -
Interface module