



USB interface,  
A/A female type  
connection with  
0.5m long cable  
LPFD0

Product designation

Product type designation

**General characteristics**

Material

Aluminium and  
zinc alloy for the  
metal part,  
polyamide for  
plastic parts

IEC degree of protection

IP65 on front

**UL technical data**

UL degree of protection

1, 2, 3R, 4, 4X,  
12, 12K on front

**Ambient conditions**

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

**Dimensions**

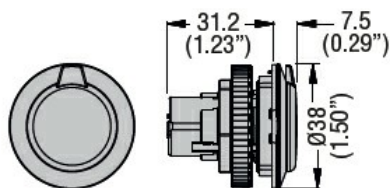

**Certifications and compliance**

Compliance

CSA C22.2 n° 14  
IEC/EN/BS 60947-1  
IEC/EN/BS 60947-5-1  
UL508

Certificates

cULus

**ETIM classification**

ETIM 8.0

EC002780 -  
Interface module