




Product designation	Push-push button actuators
Product type designation	LPFQ10
General characteristics	
Colour	Blue
Type of positions	Flush pushbutton. Push on-push off
Material	Aluminium and zinc alloy
IEC degree of protection	IP66, IP67 and IP69K

Mechanical features		
Operating force	kg-lb	<0.5Kg / 1.1lb
Mechanical life - Push-Push actuators	cycles	500000
Fixing	Without mounting adapter	
Mounting adapter	LPXAU120M	

UL technical data		
UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K	

Ambient conditions		
Temperature	Operating temperature	
	min	°C -25
	max	°C +70
	Storage temperature	
	min	°C -40
	max	°C +85

Dimensions

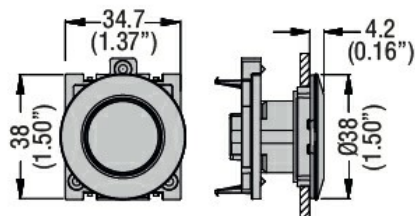

Certifications and compliance	
Compliance	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

Certificates	cULus
--------------	-------

ETIM classification

ETIM 8.0

EC000221 -
Front element for
push button