




Product designation	Push-push button actuators
Product type designation	LPFQ10
<b>General characteristics</b>	
Colour	White
Type of positions	Flush pushbutton. Push on-push off
Material	Aluminium and zinc alloy
IEC degree of protection	IP66, IP67 and IP69K

<b>Mechanical features</b>		
Operating force	kg-lb	<0.5Kg / 1.1lb
Mechanical life - Push-Push actuators	cycles	500000
Fixing	Without mounting adapter	
Mounting adapter	LPXAU120M	

<b>UL technical data</b>		
UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K	

<b>Ambient conditions</b>			
Temperature	Operating temperature	min °C	-25
		max °C	+70
	Storage temperature	min °C	-40
		max °C	+85

**Dimensions**

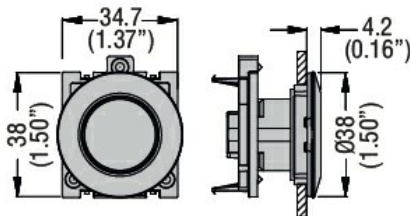

<b>Certifications and compliance</b>	
Compliance	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

Certificates	cULus
--------------	-------

**ETIM classification**

ETIM 8.0

EC000221 -  
Front element for  
push button