




Product designation	Selector switch actuator key - 2 position		
Product type designation	LPFS32		
<b>General characteristics</b>			
Colour	Black		
Type of positions	0 - 1, key extraction in 0 and 1		
Material	Aluminium and zinc alloy		
IEC degree of protection	IP66, IP67 and IP69K		
<b>Mechanical features</b>			
Mechanical life	cycles	1000000	
Fixing	Without mounting adapter		
Mounting adapter	LPXAU120M		

<b>UL technical data</b>			
UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K		

<b>Ambient conditions</b>			
Temperature			
Operating temperature		min	°C -25
		max	°C +70
Storage temperature		min	°C -40
		max	°C +85

**Dimensions**

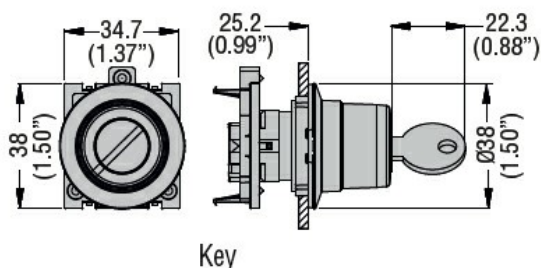

**Certifications and compliance**

Compliance	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

Certificates	cULus
--------------	-------

ETIM classification

ETIM 8.0

EC002611 -  
Control switch