




Product designation	Selector switch actuator key - 3 position
Product type designation	LPFS33
General characteristics	
Colour	Black
Type of positions	1 - 0 - 2, key extraction in 2
Material	Aluminium and zinc alloy
IEC degree of protection	IP66, IP67 and IP69K

Mechanical features	
Mechanical life	cycles 1000000
Fixing	Without mounting adapter
Mounting adapter	LPXAU120M

UL technical data	
UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K

Ambient conditions	
Temperature	
Operating temperature	
	min °C -25
	max °C +70
Storage temperature	
	min °C -40
	max °C +85

Dimensions

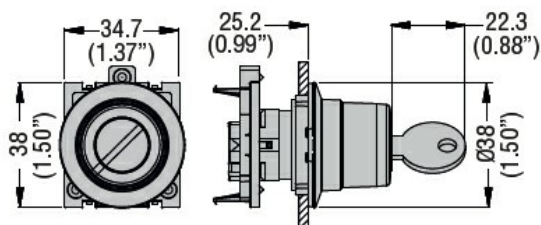

Key

Certifications and compliance

Compliance	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

Certificates	cULus
--------------	-------

ETIM classification

ETIM 8.0

EC002611 -
Control switch