




Product designation	Selector switch actuator key - 3 position
Product type designation	LPFS36
<b>General characteristics</b>	
Colour	Black
Type of positions	1 - 0 < 2, key extraction in 0
Material	Aluminium and zinc alloy
IEC degree of protection	IP66, IP67 and IP69K

<b>Mechanical features</b>	
Mechanical life	cycles 1000000
Fixing	Without mounting adapter
Mounting adapter	LPXAU120M

<b>UL technical data</b>	
UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K

<b>Ambient conditions</b>	
Temperature	
Operating temperature	
	min °C -25
	max °C +70
Storage temperature	
	min °C -40
	max °C +85

**Dimensions**

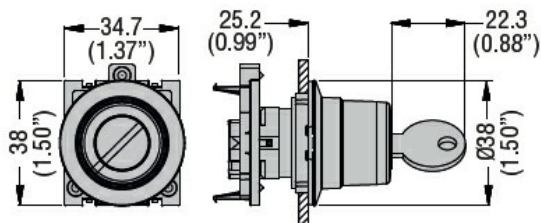

Key

**Certifications and compliance**

Compliance	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

Certificates	cULus
--------------	-------

**ETIM classification**

ETIM 8.0

EC002611 -  
Control switch