



Product designation

Mushroom head  
pushbutton,  
Latch, turn to  
release Ø  
40mm/1.6"  
LPSB664

Product type designation

**General characteristics**

Colour Black

Type of positions Mushroom head  
pushbutton

Material Aluminium and  
zinc alloy for  
metal parts and  
polyamide for  
plastic parts

IEC degree of protection IP66, IP67 and  
IP69K

**Mechanical features**

Mechanical life - Latch actuators cycles 300000

Fixing Without mounting  
adapter

Mounting adapter LPXAU120M


**UL technical data**

UL degree of protection Type1, 2, 3R, 4,  
4X, 12, 12K

**Ambient conditions**

|                       |  |     |    |     |
|-----------------------|--|-----|----|-----|
| Temperature           |  |     |    |     |
| Operating temperature |  | min | °C | -25 |
|                       |  | max | °C | +70 |
| Storage temperature   |  | min | °C | -40 |
|                       |  | max | °C | +85 |

**Dimensions**

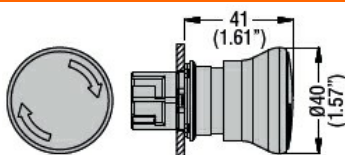

**Certifications and compliance**

|            |                     |
|------------|---------------------|
| Compliance | CSA C22.2 n° 14     |
|            | IEC/EN/BS 60947-1   |
|            | IEC/EN/BS 60947-5-1 |
|            | UL508               |

Certificates

cULus

ETIM classification

ETIM 8.0

EC000221 -  
Front element for  
push button