



Mushroom head pushbutton, Latch, pull to release Ø 40mm/1.6" LPSB674

Product designation

Product type designation

General characteristics

Colour Black

Type of positions Mushroom head pushbutton

Material Aluminium and zinc alloy for metal parts and polyamide for plastic parts

IEC degree of protection IP66, IP67 and IP69K

Mechanical features

Mechanical life - Latch actuators cycles 300000

Fixing Without mounting adapter

Mounting adapter LPXAU120M

UL technical data

UL degree of protection Type1, 2, 3R, 4, 4X, 12, 12K

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

Dimensions

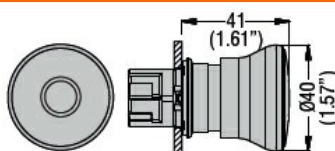

Push-pull

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC000221 -
Front element for
push button