



Double-touch
actuators, spring
return - two flush
pushbuttons
LPSB71

Product designation

Product type designation

General characteristics

Colour

Black/Black

Type of positions

Double-touch
with two flush
pushbuttons

Material

Aluminium and
zinc alloy for
metal parts and
polyamide for
plastic parts

IEC degree of protection

IP66, IP67 and
IP69K

Mechanical features

Mechanical life

cycles 1000000

Fixing

Without mounting
adapter

Mounting adapter

LPXAU120M

UL technical data

UL degree of protection

Type1, 2, 3R, 4,
4X, 12, 12K

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

Dimensions

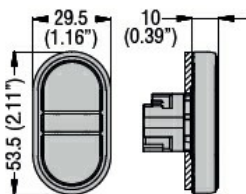

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC000029 -
Push-switch
button