



Double-touch actuators, spring return - One extended and one flush pushbuttons LPSB72

Product designation

Product type designation

General characteristics

Colour

Black/Red

Type of positions

Double-touch with one extended and one flush pushbuttons

Material

Aluminium and zinc alloy for metal parts and polyamide for plastic parts

IEC degree of protection

IP66, IP67 and IP69K

Mechanical features

Mechanical life

cycles 1000000

Fixing

Without mounting adapter

Mounting adapter

LPXAU120M

UL technical data

UL degree of protection

Type1, 2, 3R, 4, 4X, 12, 12K

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

Dimensions

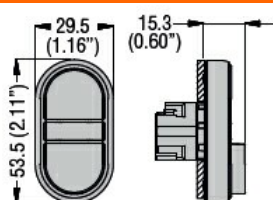

Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN/BS 60947-1

IEC/EN/BS 60947-5-1

UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC000029 -
Push-switch
button