



Double-touch  
actuators, spring  
return - One  
extended and  
one flush  
pushbuttons  
LPSB72

Product designation

Product type designation

**General characteristics**

Colour	White/Black
Type of positions	Double-touch with one extended and one flush pushbuttons
Material	Aluminium and zinc alloy for metal parts and polyamide for plastic parts
IEC degree of protection	IP66, IP67 and IP69K

**Mechanical features**

Mechanical life	cycles	1000000
Fixing	Without mounting adapter	
Mounting adapter	LPXAU120M	


**UL technical data**

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	------------------------------

**Ambient conditions**

Temperature	Operating temperature	min	°C	-25
		max	°C	+70
Storage temperature		min	°C	-40
		max	°C	+85

**Dimensions**

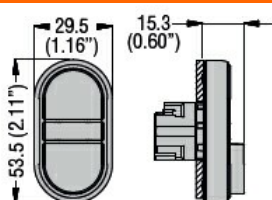

**Certifications and compliance**

Compliance

CSA C22.2 n° 14

---

IEC/EN/BS 60947-1

---

IEC/EN/BS 60947-5-1

---

UL508

---

Certificates

cULus

ETIM classification

ETIM 8.0

EC000029 -  
Push-switch  
button