



Double-touch actuators, spring return - One extended and one flush pushbuttons LPSB72

Product designation

Product type designation

**General characteristics**

Colour

White/Black

Type of positions

Double-touch with one extended and one flush pushbuttons

Material

Aluminium and zinc alloy for metal parts and polyamide for plastic parts

IEC degree of protection

IP66, IP67 and IP69K

**Mechanical features**

Mechanical life

cycles 1000000

Fixing

Without mounting adapter

Mounting adapter

LPXAU120M

**UL technical data**

UL degree of protection

Type1, 2, 3R, 4, 4X, 12, 12K

**Ambient conditions**

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

**Dimensions**

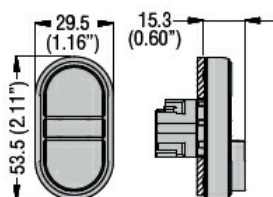

**Certifications and compliance**

Compliance

CSA C22.2 n° 14

DOUBLE-TOUCH ACTUATOR, SPRING RETURN Ø22MM PLATINUM SERIES METAL, 1  
EXTENDED AND 1 FLUSH PUSHBUTTONS. BOTH SPRING RETURN, WHITE - BLACK/I - 0

---

IEC/EN/BS 60947-1

---

IEC/EN/BS 60947-5-1

---

UL508

---

Certificates

cULus

ETIM classification

ETIM 8.0

EC000029 -  
Push-switch  
button