



Illuminated
mushroom head
button actuators -
Latch, turn to
release Ø
40mm/1.6"
LPSBL66

Product designation

Product type designation

General characteristics

Colour	Red
Type of positions	Mushroom head pushbutton
Material	Aluminium and zinc alloy for metal parts and polyamide for plastic parts
IEC degree of protection	IP66, IP67 and IP69K

Mechanical features

Mechanical life - spring return actuators	cycles	5000000
Fixing	Without mounting adapter	
Mounting adapter	LPXAU120M	


UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	------------------------------

Ambient conditions

Temperature	Operating temperature		
	min	°C	-25
	max	°C	+70
	Storage temperature		
	min	°C	-40
	max	°C	+85

Dimensions

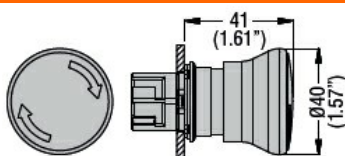

Certifications and compliance

Compliance	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC001038 -
Front element for
mushroom push-
button