




Product designation	Push-push button actuators
Product type designation	LPSQ10
General characteristics	
Colour	Yellow
Type of positions	Flush pushbutton. Push on-push off
Material	Aluminium and zinc alloy
IEC degree of protection	IP66, IP67 and IP69K

Mechanical features	
Operating force	kg-lb <0.5Kg / 1.1lb
Mechanical life - Push-Push actuators	cycles 500000
Fixing	Without mounting adapter
Mounting adapter	LPXAU120M

UL technical data	
UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K

Ambient conditions	
Temperature	
Operating temperature	
min	°C -25
max	°C +70
Storage temperature	
min	°C -40
max	°C +85

Dimensions

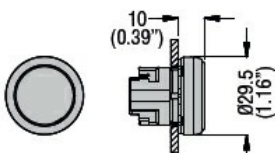

Certifications and compliance	
Compliance	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

Certificates	cULus
--------------	-------

ETIM classification	
ETIM 8.0	EC000029 - Push-switch button

