



Product designation Push-push button actuators
Product type designation LPSQ20

General characteristics

Colour Red
Type of positions Extended pushbutton. Push on-push off
Material Aluminium and zinc alloy
IEC degree of protection IP66, IP67 and IP69K

Mechanical features

Operating force kg-lb <0.5Kg / 1.1lb
Mechanical life - Push-Push actuators cycles 500000
Fixing Without mounting adapter
Mounting adapter LPXAU120M


UL technical data

UL degree of protection Type1, 2, 3R, 4, 4X, 12, 12K

Ambient conditions

Temperature
Operating temperature
min °C -25
max °C +70
Storage temperature
min °C -40
max °C +85

Dimensions

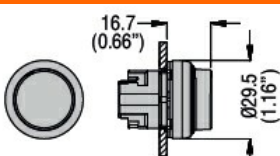

Certifications and compliance

Compliance
CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificates
cULus

ETIM classification

ETIM 8.0

EC000029 -
Push-switch
button