



Contact elements  
- with mountin  
adapter  
LPXE

Product designation

Product type designation

### Operations

Electrical life cycles 1000000

### Mechanical features

Operating force kg-lb ≤0.5Kg/1.1lb

Tightening torque for terminals max Nm 1

Terminals screw Screw

Conductor section

AWG/kcmil conductor section

max 14

IEC

max mm<sup>2</sup> 1 or 2 / 2.5

Mounting adapter LPXAU120

Weight g 29

### Ambient conditions

Temperature

Operating temperature

min °C -25


max °C +70

Storage temperature

min °C -40

max °C +85

### Wiring diagrams

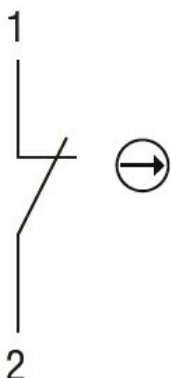

### Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN/BS 60947-1

IEC/EN/BS 60947-5-1

UL508

Certificates

CCC

---

cULus

---

EAC

---

RINA

---

UL

ETIM classification

ETIM 8.0

EC002498 -  
Accessories/spare  
parts for low-  
voltage switch  
technology