



Denumirea tipului de produs

LPZP1B5D603

Caracteristici generale

Culoare	Galben
Tipul posturilor	Buton cu cap de ciupercă
Material	Polycarbonat
grad de protectie IEC	IP66, IP67, IP69K

Conditii ambientale

Temperatura


Temperatura de Operare

min	°C	-25
max	°C	+70

Temperatura de depozitare

min	°C	-40
max	°C	+85

Dimensiuni

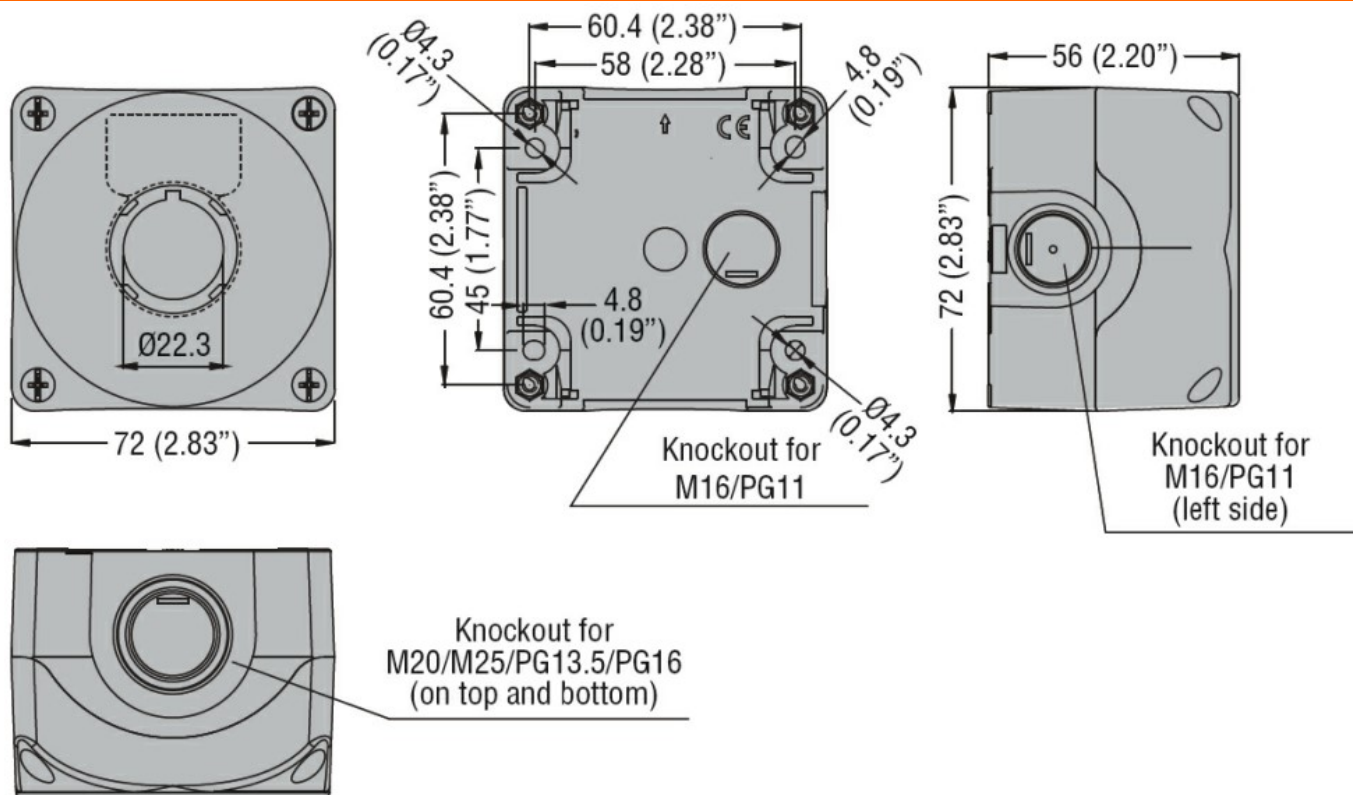

Certificari si conformitate

Conformitate

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

Certificate

EAC