



Product designation

Signal tower
Ø70mm/2.75"
8LT7S - Sound
modules

Product type designation

General characteristics

Diameter	mm - inch	70 / 2.75
Supply voltage (AC)	V	110...120
Colour		Black
IEC degree of protection		IP65
Sound module consumption (AC)	mA	40
Sound intensity	dB	75

Mechanical features

Weight	g	240
--------	---	-----



Ambient conditions

Temperature


Operating temperature

min	°C	-20
max	°C	+50

Dimensions

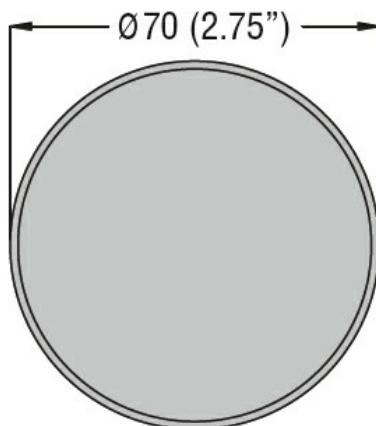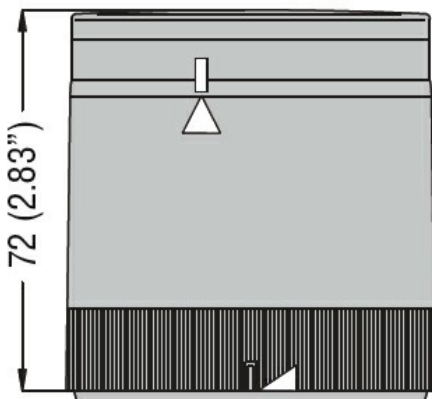

Wiring diagrams

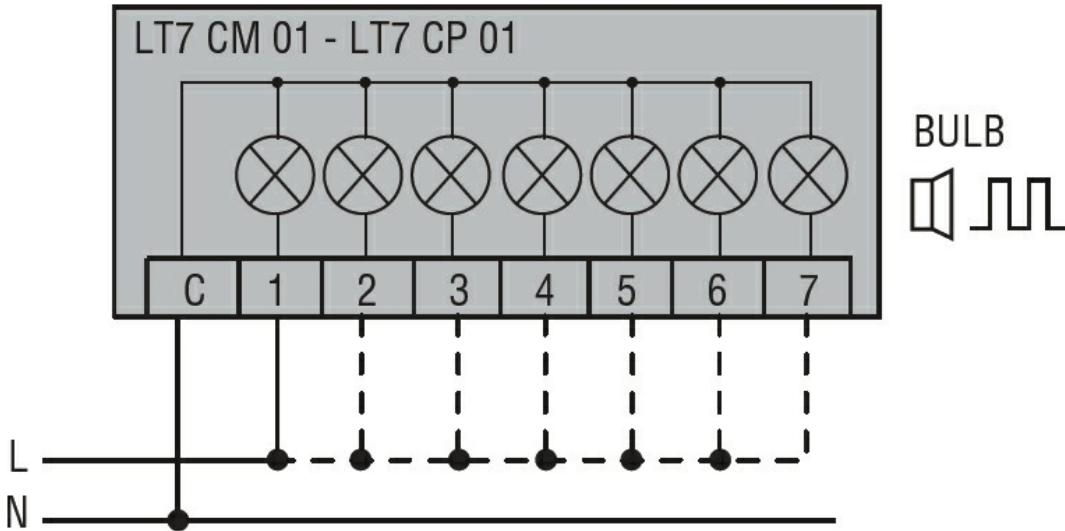

Connect terminals C and 1 as indicated to power the first module.
 If other modules are fitted, the respective terminals must be
 connected accordingly.

Certifications and compliance

Compliance

CSA C22.2 n°14
 IEC/EN 60947-1
 IEC/EN 60947-5-1
 UL508

Certificates

cULus
 EAC

ETIM classification

ETIM 8.0

EC001261 -
 Acoustic module
 for signal tower