



Signal tower
Ø50mm/1.97"
LTN50

Product designation

Product type designation

General characteristics

| | | |
|--------------------------|-----------|-----------|
| Diameter | mm - inch | 50 / 1.97 |
| Colour | | Green |
| IEC degree of protection | | IP65 |
| Power consumption | VA | 1.2 |


Mechanical features

| | | |
|--------|---|----|
| Weight | g | 37 |
|--------|---|----|

Ambient conditions

| | | | |
|-------------|-----------------------|----|-----|
| Temperature | Operating temperature | | |
| | min | °C | -30 |
| | max | °C | +50 |

Dimensions

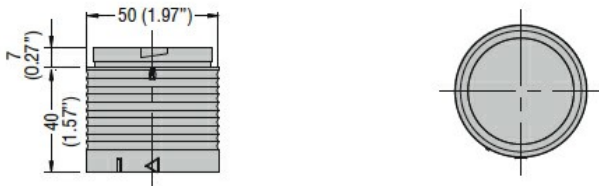

Certifications and compliance

| | |
|------------|---------------------|
| Compliance | CSA C22.2 n° 14 |
| | IEC/EN/BS 60947-1 |
| | IEC/EN/BS 60947-5-1 |
| | UL508 |

| | |
|--------------|-------|
| Certificates | cULus |
|--------------|-------|

ETIM classification

| | |
|----------|--|
| ETIM 8.0 | EC000232 - Optical module for signal tower |
|----------|--|