



Denumirea produsului

Coloane
 iluminate Ø70
 mm

Denumirea tipului de produs

8TL7GL - Module
 ușoare

Caracteristici generale

Diametru	mm - inch	70 / 2.75
Tensiune de alimentare (AC)	V	24
Tensiune de alimentare (DC)	V	24
Culoare		Portocaliu
grad de protectie IEC		IP65

Caracteristici mecanice

Greutate	g	83
----------	---	----


Conditii ambientale

Temperatura	Temperatura de Operare		
		min	°C -20
		max	°C +50

Dimensiuni



Diagrame de cablare

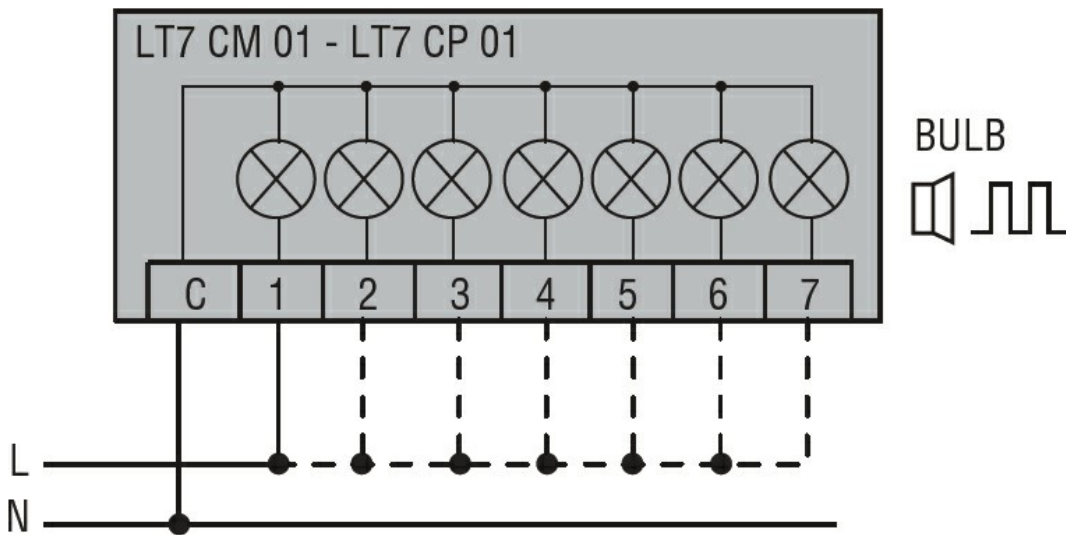

Connect terminals C and 1 as indicated to power the first module.
If other modules are fitted, the respective terminals must be connected accordingly.

Certificari si conformitate

Conformitate

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

Certificate

cULus

EAC

Clasificare ETIM

ETIM 8.0

EC000232 -
Modul optic
pentru turn de
semnalizare