



Denumirea produsului

Coloane  
 iluminate Ø70  
 mm

Denumirea tipului de produs

8TL7GL - Module  
 ușoare

**Caracteristici generale**

|                             |           |           |
|-----------------------------|-----------|-----------|
| Diametru                    | mm - inch | 70 / 2.75 |
| Tensiune de alimentare (AC) | V         | 24        |
| Tensiune de alimentare (DC) | V         | 24        |
| Culoare                     |           | Galben    |
| grad de protectie IEC       |           | IP65      |

**Caracteristici mecanice**

|          |   |    |
|----------|---|----|
| Greutate | g | 83 |
|----------|---|----|


**Conditii ambientale**

|             |                        |     |        |
|-------------|------------------------|-----|--------|
| Temperatura | Temperatura de Operare |     |        |
|             |                        | min | °C -20 |
|             |                        | max | °C +50 |

**Dimensiuni**



Diagrame de cablare

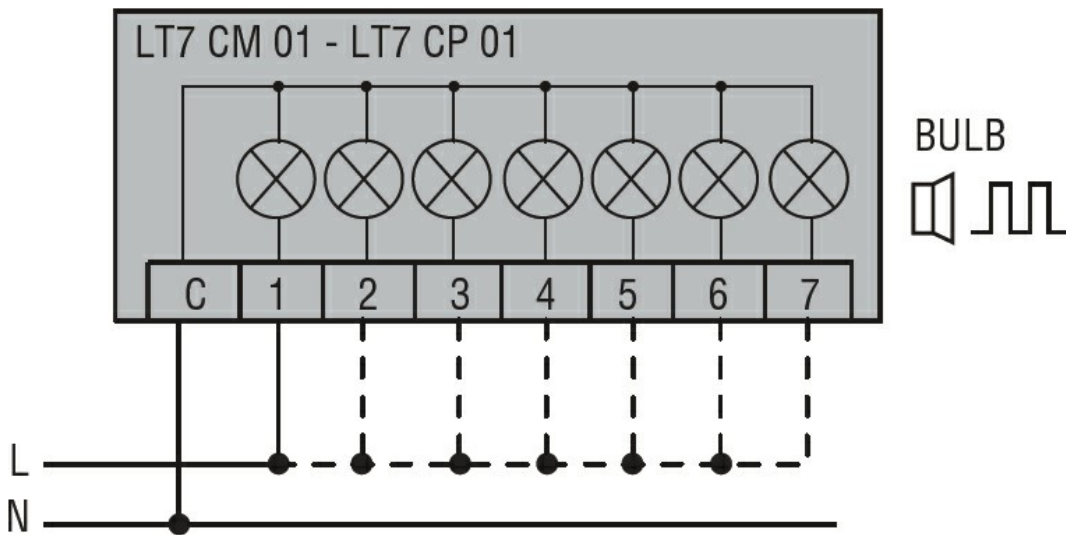

Connect terminals C and 1 as indicated to power the first module.  
 If other modules are fitted, the respective terminals must be connected accordingly.

Certificari si conformitate

Conformitate

CSA C22.2 n° 14

---

IEC/EN 60947-1

---

IEC/EN 60947-5-1

---

UL508

---

Certificate

cULus

---

EAC

---

Clasificare ETIM

ETIM 8.0

EC000232 -  
Modul optic  
pentru turn de  
semnalizare