



Denumirea produsului

Coloane  
 iluminate Ø70  
 mm

Denumirea tipului de produs

8TL7GL - Module  
 ușoare

**Caracteristici generale**

Diametru	mm - inch	70 / 2.75
Tensiune de alimentare (AC)	V	24
Tensiune de alimentare (DC)	V	24
Culoare		alb
grad de protectie IEC		IP65


**Caracteristici mecanice**

Greutate	g	83
----------	---	----


**Conditii ambientale**

Temperatura	Temperatura de Operare		
		min	°C -20
		max	°C +50

**Dimensiuni**

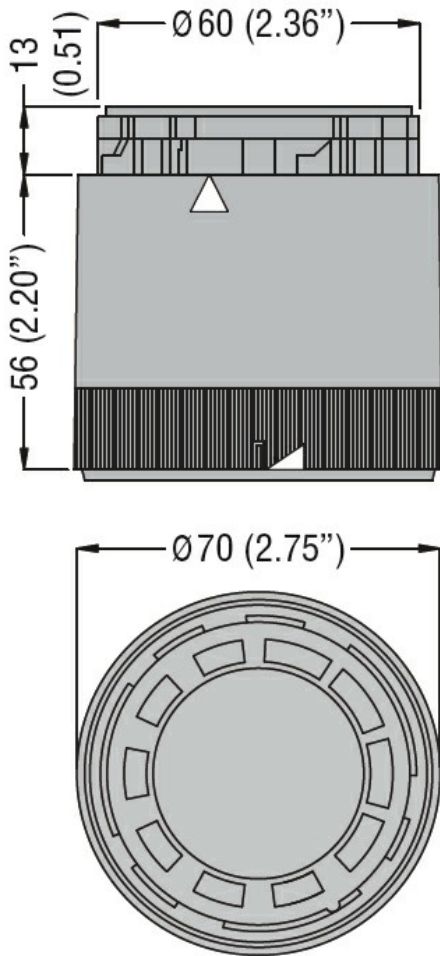

Diagrame de cablare

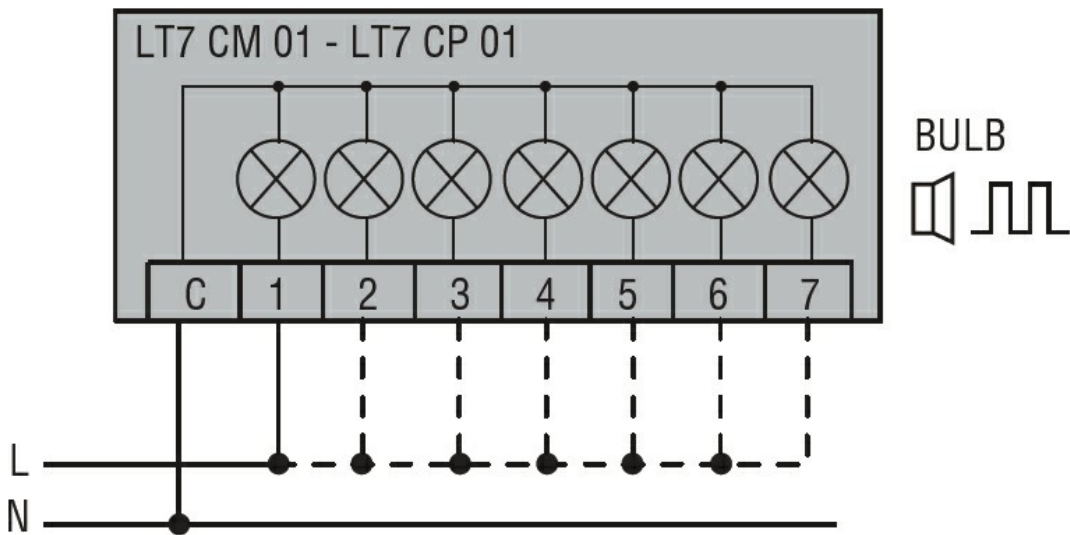

Connect terminals C and 1 as indicated to power the first module.  
If other modules are fitted, the respective terminals must be connected accordingly.

Certificari si conformitate

Conformitate

CSA C22.2 n° 14

---

IEC/EN 60947-1

---

IEC/EN 60947-5-1

---

UL508

---

Certificate

cULus

---

EAC

---

Clasificare ETIM

ETIM 8.0

EC000232 -  
Modul optic  
pentru turn de  
semnalizare