



Denumirea produsului

Coloane
 iluminate Ø70
 mm

Denumirea tipului de produs

8TL7GL - Module
 ușoare

Caracteristici generale

| | | |
|-----------------------------|-----------|-----------|
| Diametru | mm - inch | 70 / 2.75 |
| Tensiune de alimentare (AC) | V | 110...120 |
| Culoare | | Galben |
| grad de protectie IEC | | IP65 |

Caracteristici mecanice

| | | |
|----------|---|----|
| Greutate | g | 83 |
|----------|---|----|


Conditii ambientale

| | | | | |
|-------------|------------------------|-----|----|-----|
| Temperatura | Temperatura de Operare | | | |
| | | min | °C | -20 |
| | | max | °C | +50 |

Dimensiuni



Diagrame de cablare

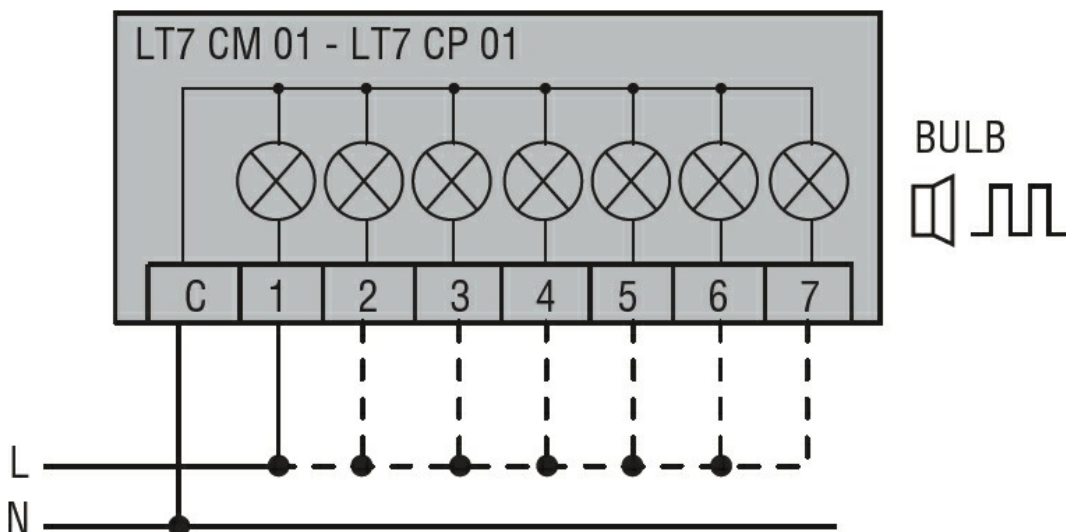

Connect terminals C and 1 as indicated to power the first module.
 If other modules are fitted, the respective terminals must be connected accordingly.

Certificari si conformitate

Conformitate

CSA C22.2 n° 14

IEC/EN 60947-1
IEC/EN 60947-5-1
UL508

Certificate

cULus
EAC

Clasificare ETIM

ETIM 8.0

EC000232 -
Modul optic
pentru turn de
semnalizare