



Denumirea produsului

Coloane
 iluminate Ø70
 mm

Denumirea tipului de produs

8TL7GL - Module
 ușoare

Caracteristici generale

Diametru	mm - inch	70 / 2.75
Tensiune de alimentare (AC)	V	230...240
Culoare		Roșu
grad de protectie IEC		IP65


Caracteristici mecanice

Greutate	g	83
----------	---	----


Conditii ambientale

Temperatura	Temperatura de Operare			
		min	°C	-20
		max	°C	+50

Dimensiuni

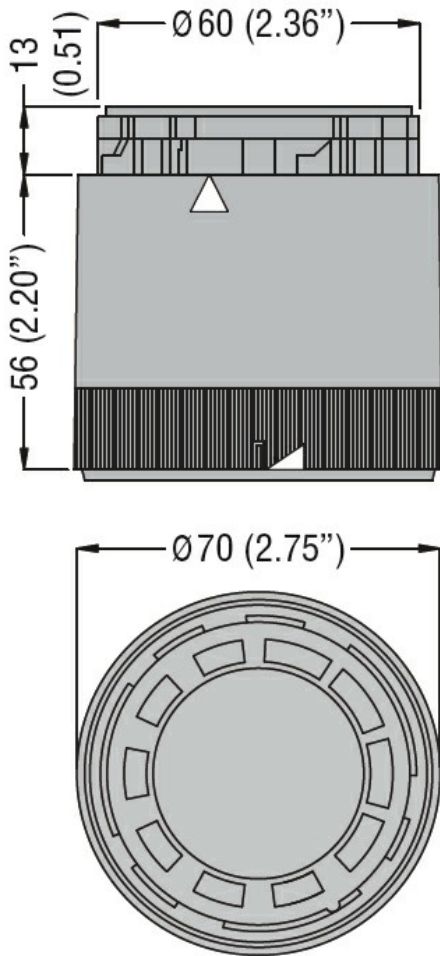

Diagrame de cablare

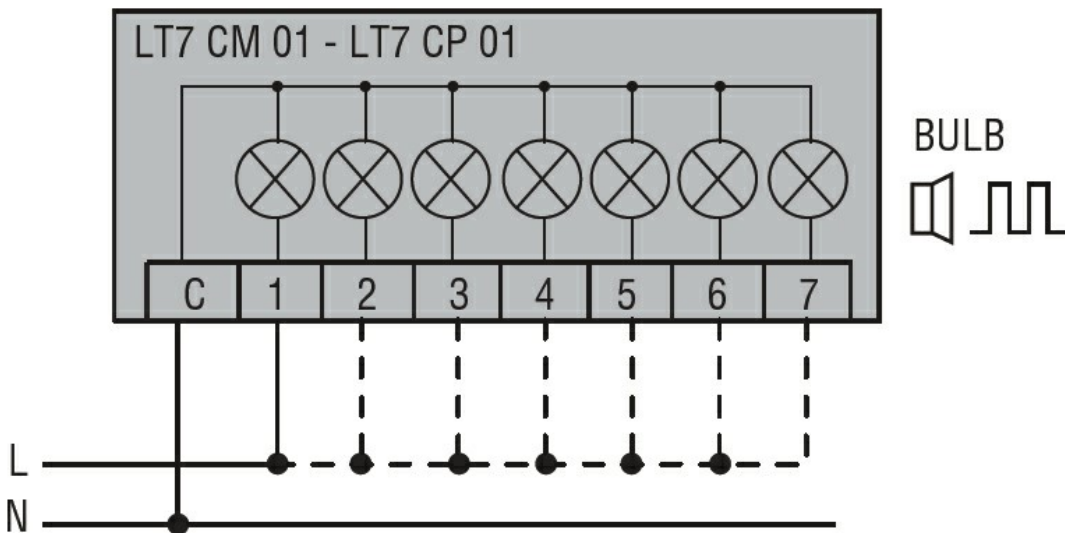

Connect terminals C and 1 as indicated to power the first module.
 If other modules are fitted, the respective terminals must be connected accordingly.

Certificari si conformitate

Conformitate

CSA C22.2 n° 14

IEC/EN 60947-1
IEC/EN 60947-5-1
UL508

Certificate

cULus
EAC

Clasificare ETIM

ETIM 8.0

EC000232 -
Modul optic
pentru turn de
semnalizare