



Coloane  
 luminoase Ø50  
 mm  
 LTN50

Denumirea produsului

Denumirea tipului de produs

**Caracteristici generale**

Diametru	mm - inch	50 / 1.97
grad de protectie IEC		IP20
Consumul de energie	VA	1.7
Intensitatea sunetului	dB	100

**Caracteristici mecanice**

Greutate	g	48
----------	---	----


**Conditii ambientale**

Temperatura

Temperatura de Operare

min	°C	-30
max	°C	+50

**Dimensiuni**

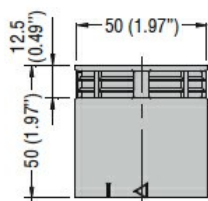

**Certificari si conformitate**

Conformitate

- CSA C22.2 n° 14
- IEC/EN/BS 60947-1
- IEC/EN/BS 60947-5-1
- UL508

Certificate

cULus

**Clasificare ETIM**

ETIM 8.0

EC001261 -  
 Element acustic  
 pentru coloana  
 de semnal