



Coloane  
luminoase Ø50  
mm  
LTN50

Denumirea produsului

Denumirea tipului de produs

**Caracteristici generale**

Diametru mm - inch 50 / 1.97

Material Metal

**Caracteristici mecanice**

Greutate g 27


**Conditii ambientale**

Temperatura

Temperatura de Operare

min °C -30  
max °C +50

**Dimensiuni**

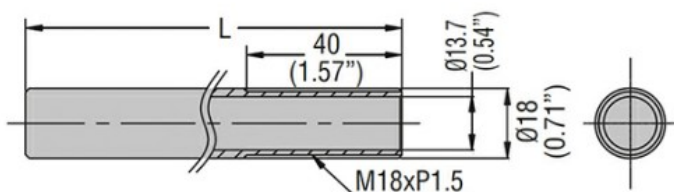

Type	L (mm/in)
LTP50P050T	50 (1.97")
LTP50P100T	100 (3.94")
LTP50P250T	250 (9.84")
LTP50P400T	400 (15.75")

**Certificari si conformitate**

Conformitate

CSA C22.2 n° 14  
IEC/EN/BS 60947-1  
IEC/EN/BS 60947-5-1  
UL508

Certificate

cULus

**Clasificare ETIM**

ETIM 8.0

EC001155 - Tub  
pentru coloana  
de semnal